


Connection cable

VDOAF030MSS0001H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11383

When selecting an alternative article and accessories please note that technical data may differ!

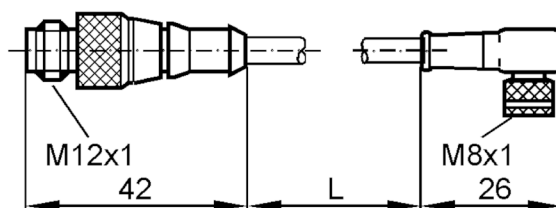

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Protection class

III

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E10990



Connection cable

VDOAF030MSS0001H03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

