

E10996




Jumper cable with valve plug

VVDAB031--S00,6H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11422

When selecting an alternative article and accessories please note that technical data may differ!

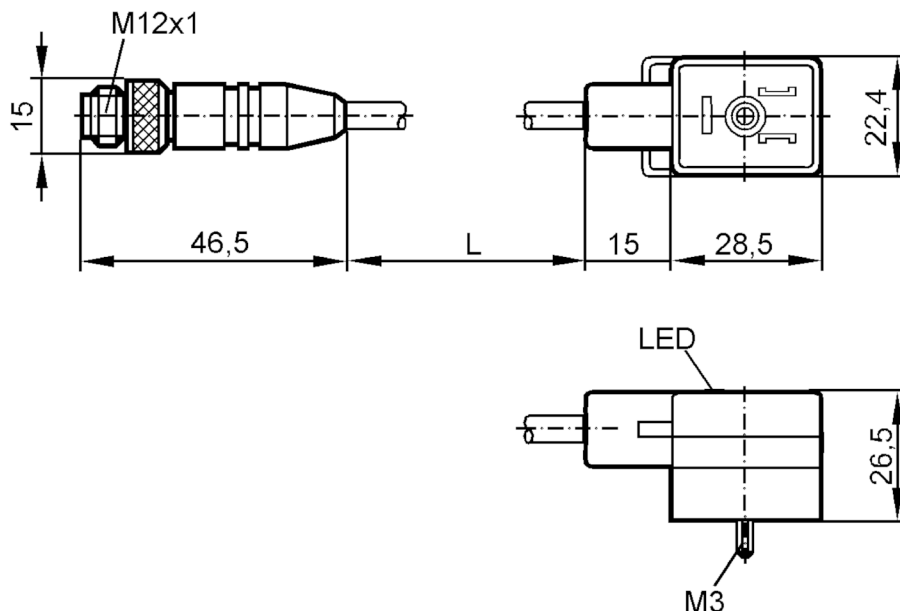

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Dimensions	[mm]	15 x 15 x 46.5
Materials	TPU	
Moulded-body material	TPU	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	1 x LED, yellow
Аксессуары		
Items supplied	screw	
	panel for labelling	
Remarks		
Pack quantity	1 pcs.	

E10996




Jumper cable with valve plug

VVDAB031--S00,6H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.6 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection

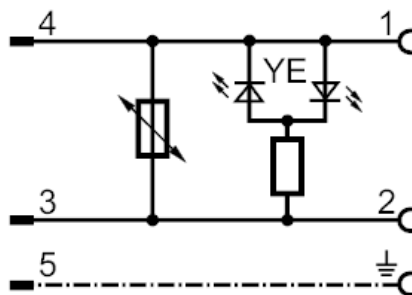

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

