


E10007



Connecting cable with socket

ADOAH042ZDS0002E03

Article no longer available - archive entry

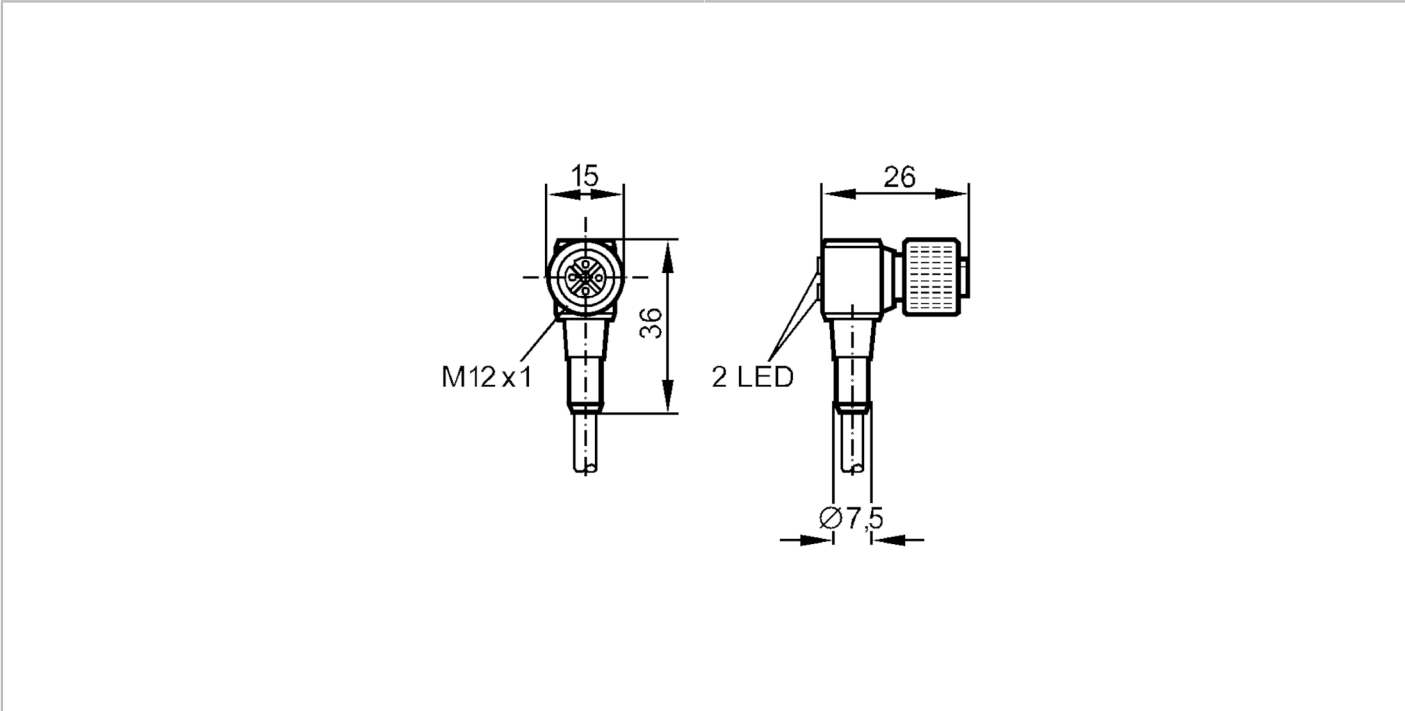

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		NPN
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	36 x 15 x 26
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10007



Connecting cable with socket

ADOAH042ZDS0002E03

Electrical connection


Cable: 2 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection

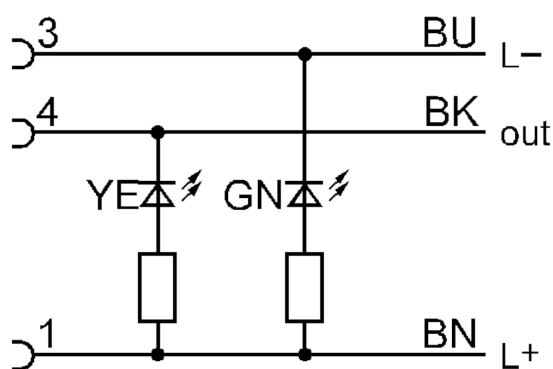

BN =
BK =
BU =

Core colours :
brown
black
blue