

E10011



Connecting cable with socket

ADOAH042ZDS0010E03

Article no longer available - archive entry



Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design NPN

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 36 x 15 x 26

Materials PUR

Moulded-body material PUR

Material nut diecast zinc, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10011



Connecting cable with socket

ADOAH042ZDS0010E03

Electrical connection


Cable: 10 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection

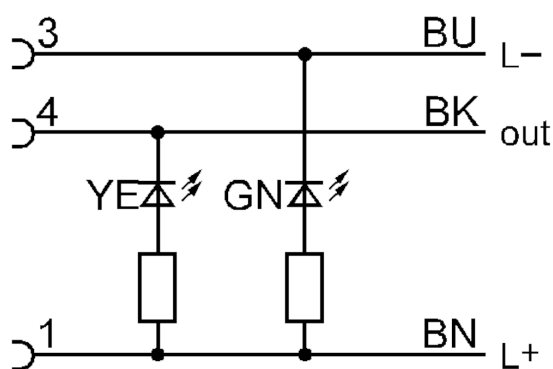

BN =
BK =
BU =

Core colours :
brown
black
blue