




Wirable socket

SDOAC030--SFKPG

Article no longer available - archive entry

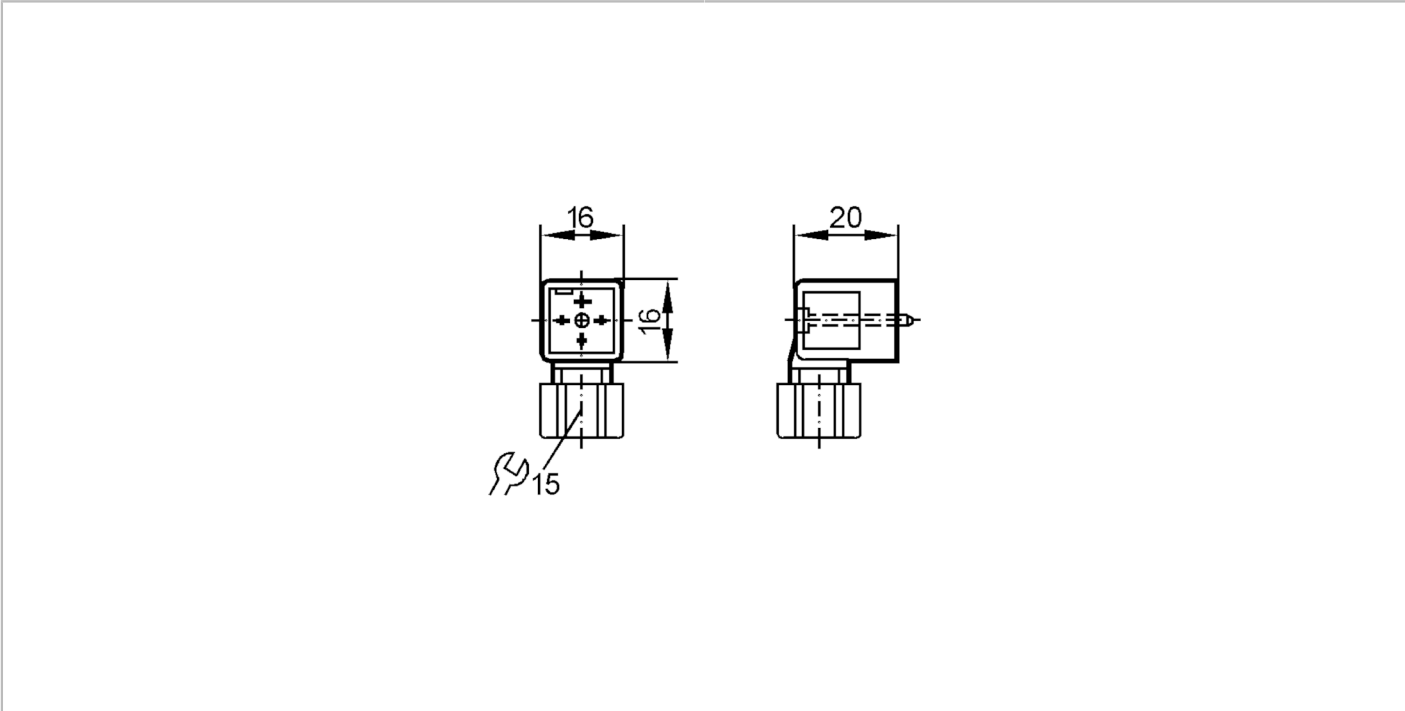

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Materials	PA
Moulded-body material	PA

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø ...6.5 mm

Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: PA



E10059

Wirable socket

SDOAC030--SFKPG



Connection

