

E10088




Wirable socket

SDOAH042PLSFKPG

Article no longer available - archive entry

Alternative articles: E11510
When selecting an alternative article and accessories please note that technical data may differ!

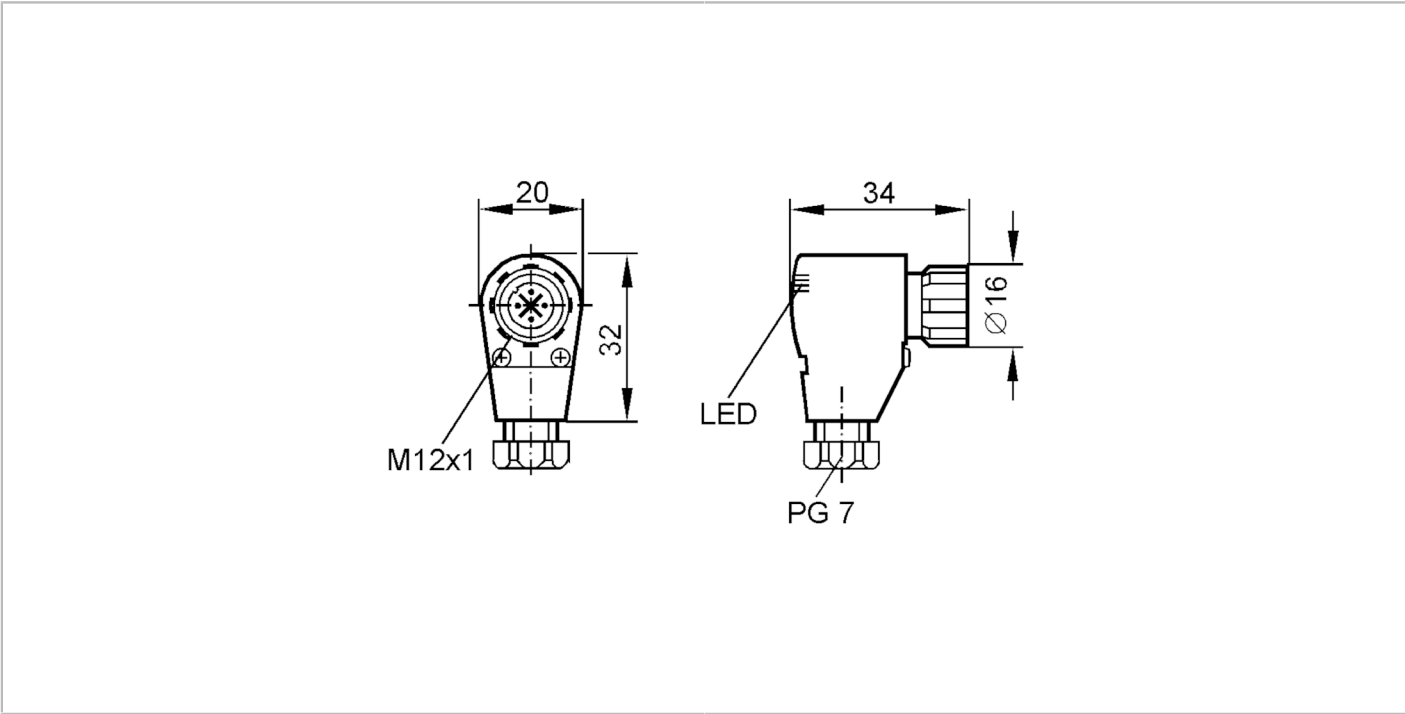

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-30...80
Protection		IP 65
Mechanical data		
Dimensions	[mm]	20 x 34 x 32
Materials		PA
Moulded-body material		PA
Material nut		PA
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10088



Wirable socket

 
SDOAH042PLSFKPG

Electrical connection

terminals: ...0.5 mm²; Cable gland: PG 7

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: PA



Connection

