



Adapter plug

ESTGB030MSS00,3E03 (PG13,5)

Article no longer available - archive entry

No scale drawing available

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 600 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...100
Protection		IP 68

Mechanical data

Weight	[g]	45.36
Mounting thread		1/2" NPT
Materials		aluminium anodised
Moulded-body material		aluminium, anodised

Remarks

 
Pack quantity	1 pcs.
---------------	--------

Electrical connection

, PVC; 3 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: aluminium, anodised; Contacts: gold-plated




E10103



Adapter plug

ESTGB030MSS00,3E03 (PG13,5)

Connection

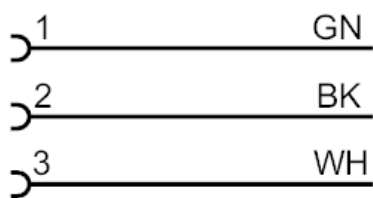

BK =	Core colours :
GN =	black
WH =	green
	white