


E10110



Adapter plug

ESTGB040MSS00,3E03 (PG13,5)

Article no longer available - archive entry

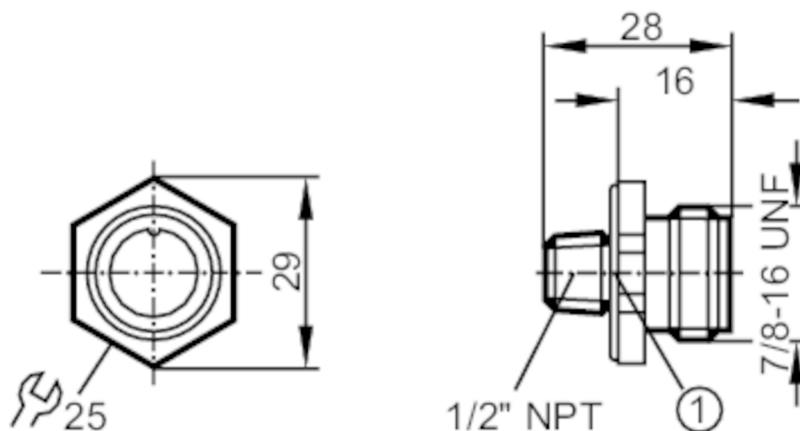

1 O-ring

Application

Special feature Gold-plated contacts

Electrical data

Operating voltage [V] < 600 AC/DC

Operating conditions

Ambient temperature [°C] -20...100

Protection IP 68

Mechanical data

Weight [g] 45.5

Mounting thread 1/2" NPT

Materials aluminium anodised

Moulded-body material aluminium, anodised

Remarks

Pack quantity 1 pcs.

E10110



Adapter plug

ESTGB040MSS00,3E03 (PG13,5)

Electrical connection


, PVC; 4 x 0.34 mm² / AWG 22

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: aluminium, anodised; Contacts: gold-plated



Connection

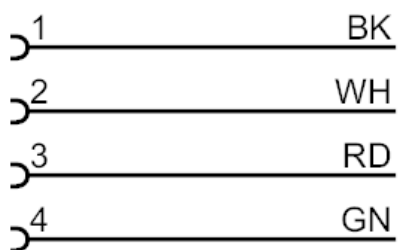

BK =	Core colours :
GN =	black
RD =	green
WH =	red
	white