

# E10139



## Connecting cable with socket

ADOGH040MSS0002A03

Article no longer available - archive entry

Alternative articles: EVC001  
When selecting an alternative article and accessories please note that technical data may differ!



| Electrical data       |      |                      |
|-----------------------|------|----------------------|
| Operating voltage     | [V]  | < 250 AC / < 300 DC  |
| Operating conditions  |      |                      |
| Ambient temperature   | [°C] | -25...90             |
| Protection            |      | IP 67                |
| Mechanical data       |      |                      |
| Dimensions            | [mm] | 15 x 15 x 43         |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |
| Remarks               |      |                      |
| Pack quantity         |      | 1 pcs.               |

# E10139



## Connecting cable with socket

ADOGH040MSS0002A03

### Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



### Connection

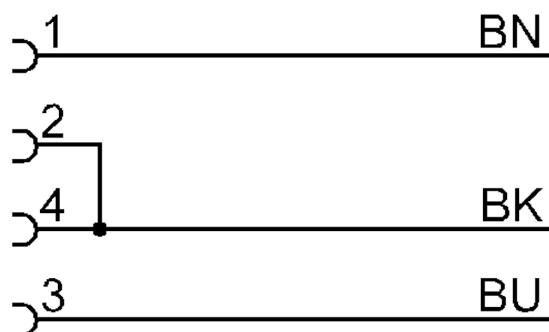

BN =  
BK =  
BU =

Core colours :  
brown  
black  
blue