

# E10160




## Connecting cable with socket

ADOAH042MSS0002B03

Article no longer available - archive entry

Alternative articles: EVC007  
When selecting an alternative article and accessories please note that technical data may differ!

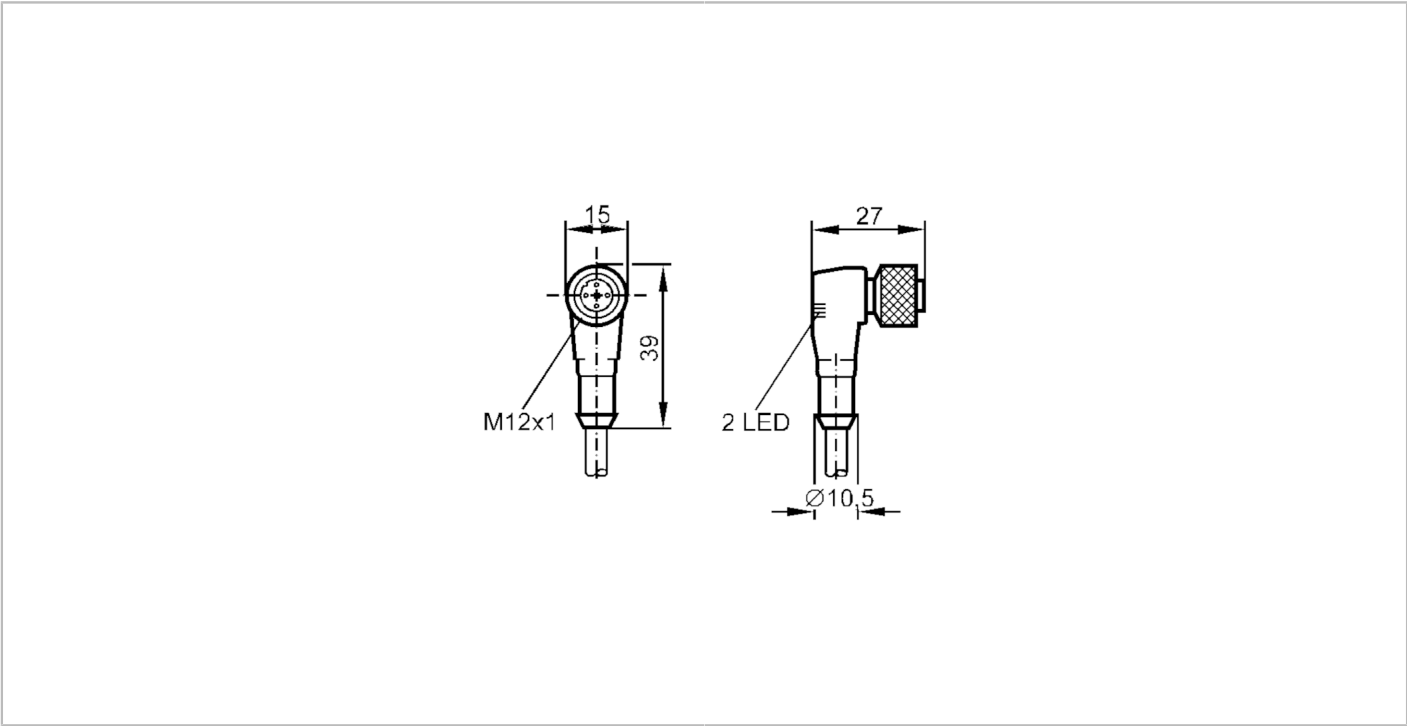

| Electrical data               |                  |                      |
|-------------------------------|------------------|----------------------|
| Operating voltage             | [V]              | 10...30 DC           |
| Outputs                       |                  |                      |
| Electrical design             |                  | PNP                  |
| Operating conditions          |                  |                      |
| Ambient temperature           | [°C]             | -25...90             |
| Protection                    |                  | IP 67                |
| Mechanical data               |                  |                      |
| Dimensions                    | [mm]             | 27 x 15 x 39         |
| Materials                     |                  | TPU transparent      |
| Moulded-body material         |                  | TPU, transparent     |
| Material nut                  |                  | brass, nickel-plated |
| Displays / operating elements |                  |                      |
| Display                       | switching status | 1 x LED, yellow      |
|                               | operation        | 1 x LED, green       |
| Remarks                       |                  |                      |
| Pack quantity                 |                  | 1 pcs.               |

# E10160



## Connecting cable with socket

ADOAH042MSS0002B03

### Electrical connection

Cable: 2 m, PUR, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated



### Connection



|      |                |
|------|----------------|
| BN = | Core colours : |
| BK = | brown          |
| BU = | black          |
|      | blue           |