

E10194




Connecting cable with socket

ADOAG030--S0002E03

Article no longer available - archive entry

Alternative articles: E10217

When selecting an alternative article and accessories please note that technical data may differ!

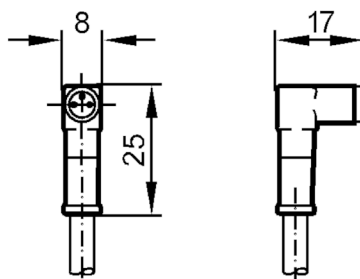

Electrical data

Operating voltage	[V]	< 60 AC/DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	17 x 8 x 25
Materials		PUR
Moulded-body material		PUR

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10194



Connecting cable with socket

ADOAG030--S0002E03

Electrical connection


Cable: 2 m, PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR



Connection

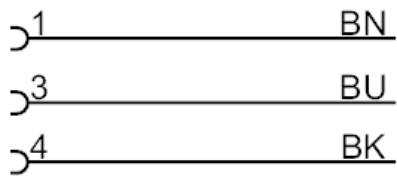

BN = Core colours :
brown
BK = black
BU = blue