


E10215



Connecting cable with socket

ADOGH040MSS0005A02


Article no longer available - archive entry

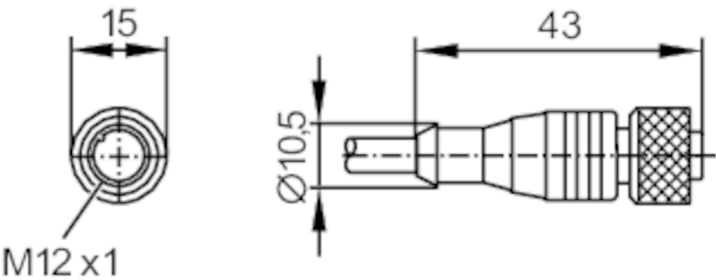

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm²	

Electrical connection - socket	
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm	

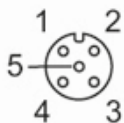


E10215



Connecting cable with socket

ADOGH040MSS0005A02

Connection

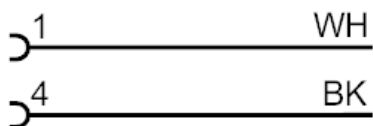

BK =	Core colours :
WH =	black
	white