


E10218



Connecting cable with socket

ADOAG032--S0002A03

Article no longer available - archive entry

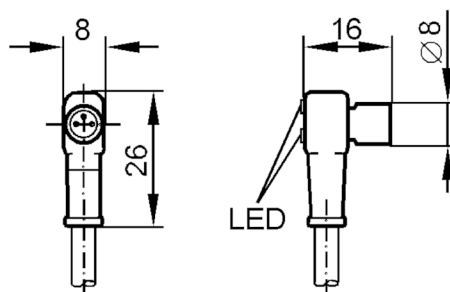

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] 10...30 DC

Protection class III

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 65

Mechanical data

Materials TPU transparent

Moulded-body material TPU, transparent

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10218



Connecting cable with socket


ADOAG032--S0002A03

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

 Connector: 1 x M8, angled; coding: A; Moulded body: TPU, transparent; Locking: snap-in



Connection

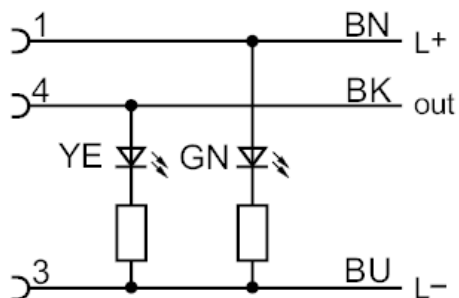

BK =	Core colours :
BN =	black
BU =	brown
	blue