


Connecting cable with socket

ADOAG032--S0005A03

Article no longer available - archive entry

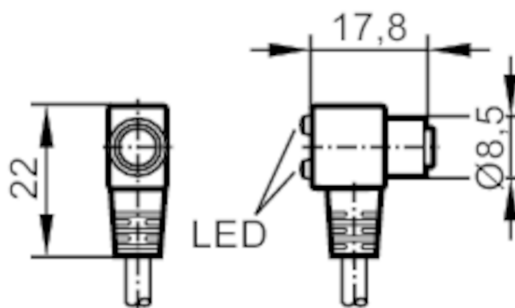

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Outputs

Electrical design

PNP

Operating conditions

Ambient temperature

[°C]

-25...85

Protection

IP 65

Mechanical data

Weight

[g]

146.6

Materials

TPU transparent

Moulded-body material

TPU, transparent

Displays / operating elements

Display

switching status

1 x LED, yellow

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.

E10219



Connecting cable with socket


ADOAG032--S0005A03

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.5 mm; 3 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

 Connector: 1 x M8, angled; coding: A; Moulded body: TPU, transparent; Locking: snap-in



Connection

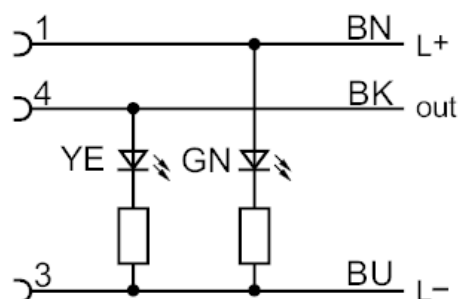

BK =	Core colours :
BN =	black
BU =	brown
	blue