


E10250



Connecting cable with socket

ADOAH040ZDS0005A03

Article no longer available - archive entry

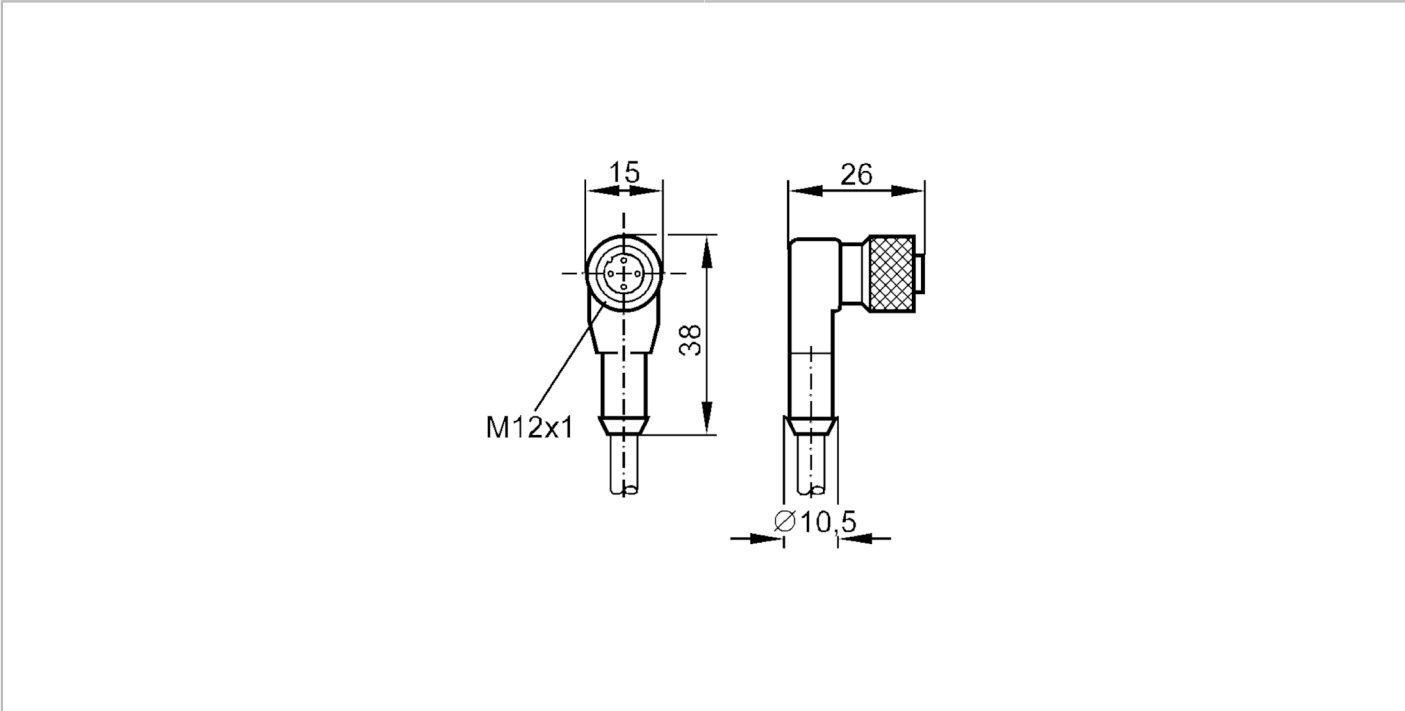

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



E10250



Connecting cable with socket

ADOAH040ZDS0005A03

Connection



BN =
BK =
BU =

Core colours :
brown
black
blue