


Connecting cable with socket

ADOGH040ZDS0005A03

Article no longer available - archive entry

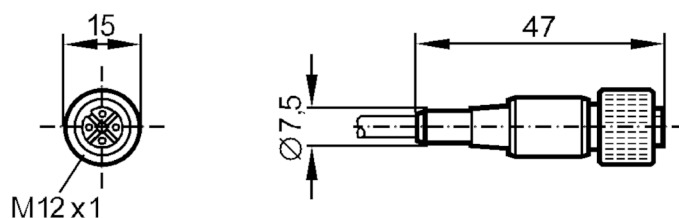

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	15 x 15 x 47
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

 Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated




E10252



Connecting cable with socket

ADOGH040ZDS0005A03

Connection

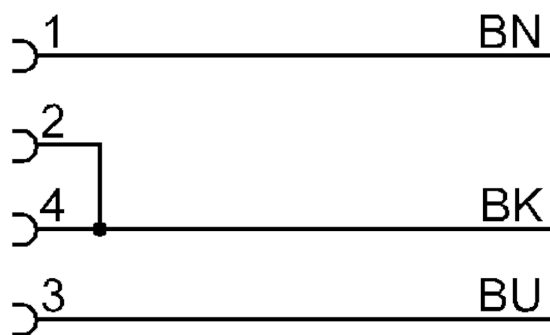

BN =
BK =
BU =

Core colours :
brown
black
blue