


Connecting cable with socket

ADOAG032--S0010A03

Article no longer available - archive entry

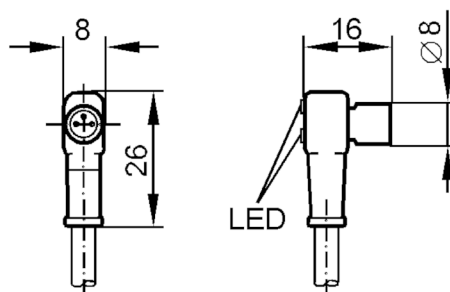

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Materials	TPU transparent
Moulded-body material	TPU, transparent

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10289



Connecting cable with socket


ADOAG032--S0010A03

Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - socket

 Connector: 1 x M8, angled; coding: A; Moulded body: TPU, transparent; Locking: snap-in



Connection

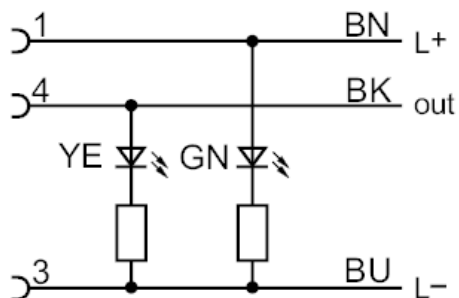

BK =	Core colours :
BN =	black
BU =	brown
	blue