


E10290



Splitter box

ZDO4H045MSS0,03A07

Article no longer available - archive entry

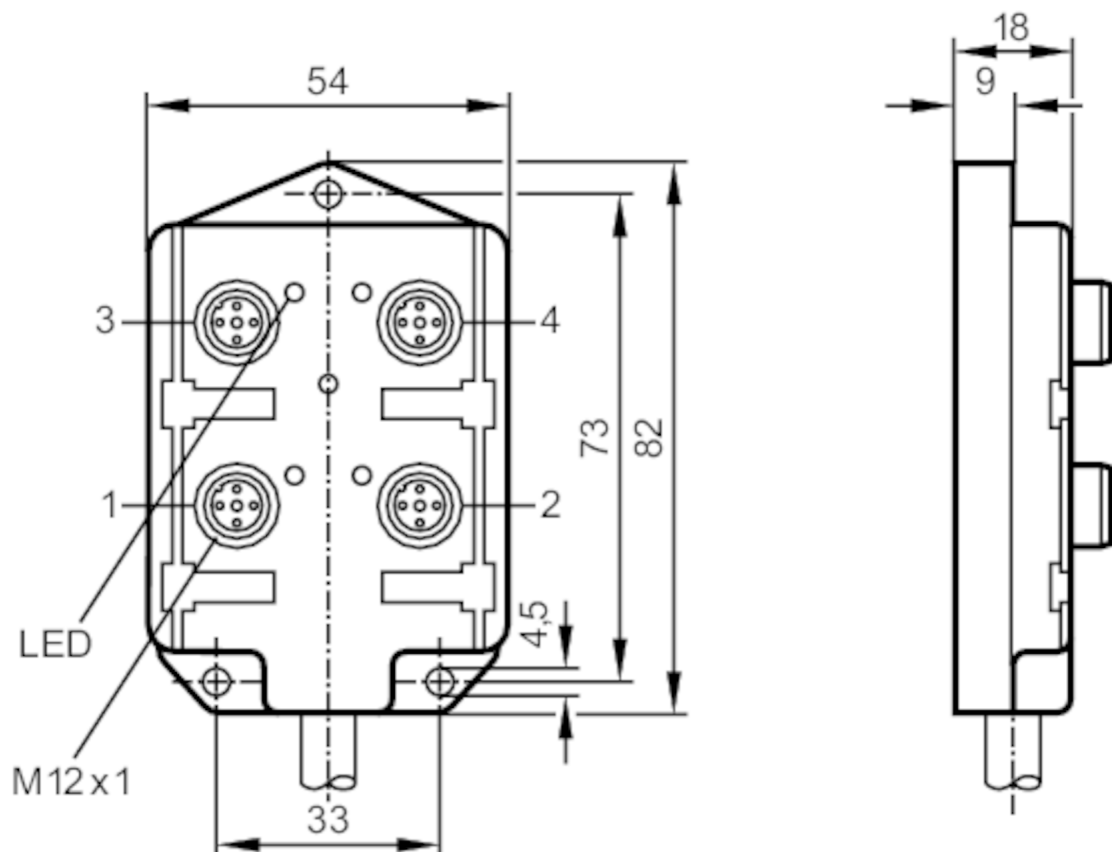

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	18 x 54 x 82
Number of ports splitter box		4

Displays / operating elements

Display	switching status	4 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10290



Splitter box


ZDO4H045MSS0,03A07

Electrical connection

Cable: 0.35 m, PUR / PVC; 4 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 4 x M12; coding: A; Tightening torque: 0.5 Nm

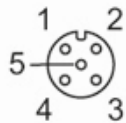

Connection

BN	1 (1...4)	C
BU	3 (1...4)	C
GN/YE	5 (1...4)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C

	Core colours :
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
WH =	white
YE =	yellow