

E10293




Connecting cable with socket

ADOGH040MSS0002F03

Article no longer available - archive entry

Alternative articles: E10915
When selecting an alternative article and accessories please note that technical data may differ!

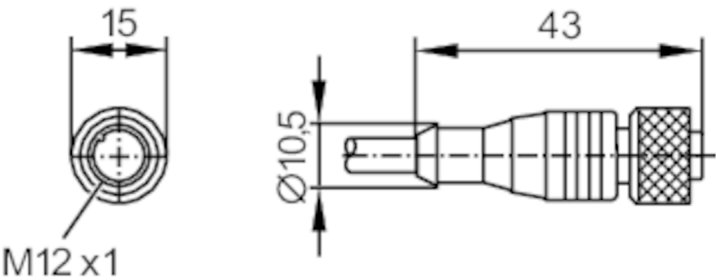

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, anti-spatter
Remarks		
Pack quantity		1 pcs.

E10293



Connecting cable with socket

ADOGH040MSS0002F03

Electrical connection

Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, anti-spatter; Tightening torque: 0.5 Nm



Connection



BN =
BK =
BU =

Core colours :
brown
black
blue