


E10318



Connecting cable with socket

ADOAH042VAS0005E03

Article no longer available - archive entry

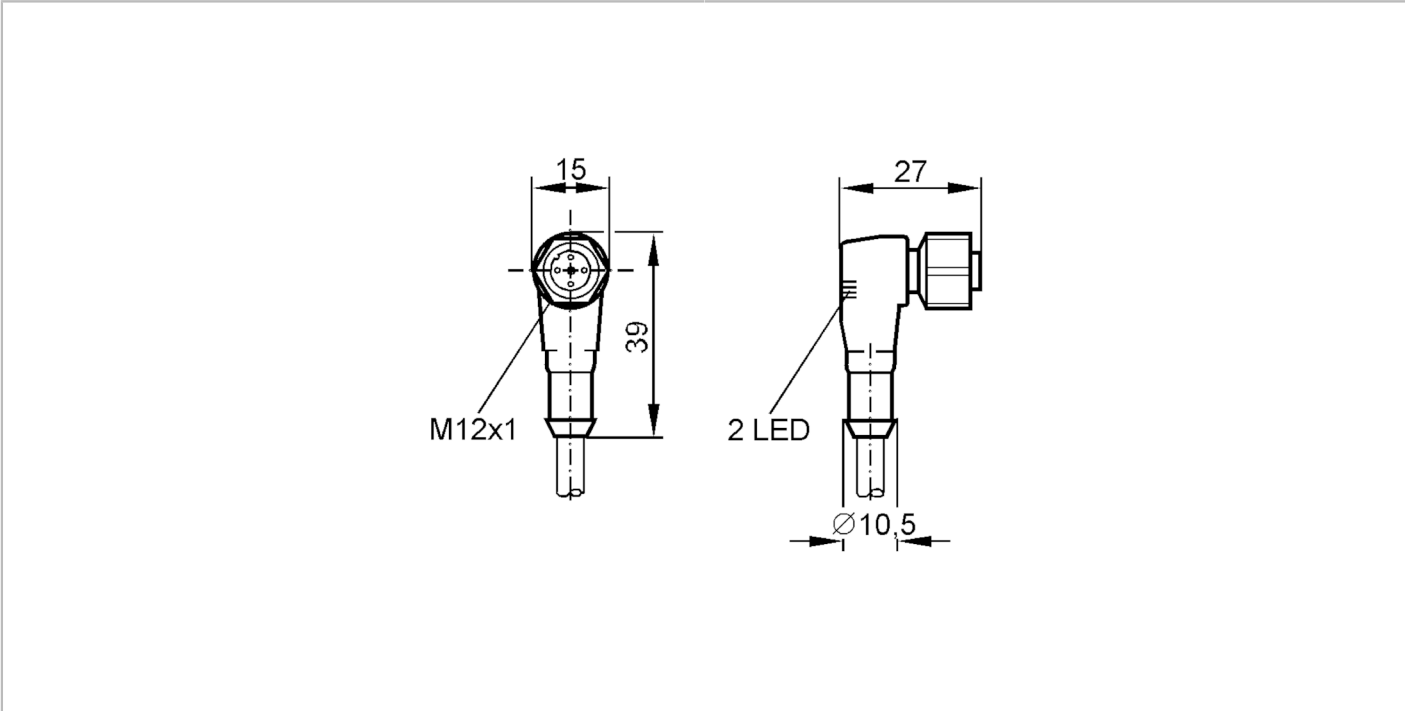

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU transparent
Moulded-body material		TPU, transparent
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10318



Connecting cable with socket

 
ADOAH042VAS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm



Connection

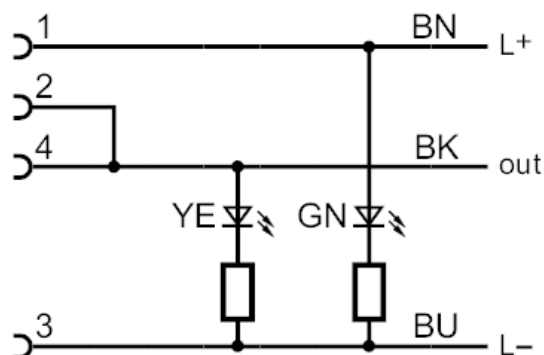

BK =	Core colours :
BN =	black
BU =	brown
	blue