


E10334



Connecting cable with socket


ADOAH040VAS0010E02

Article no longer available - archive entry

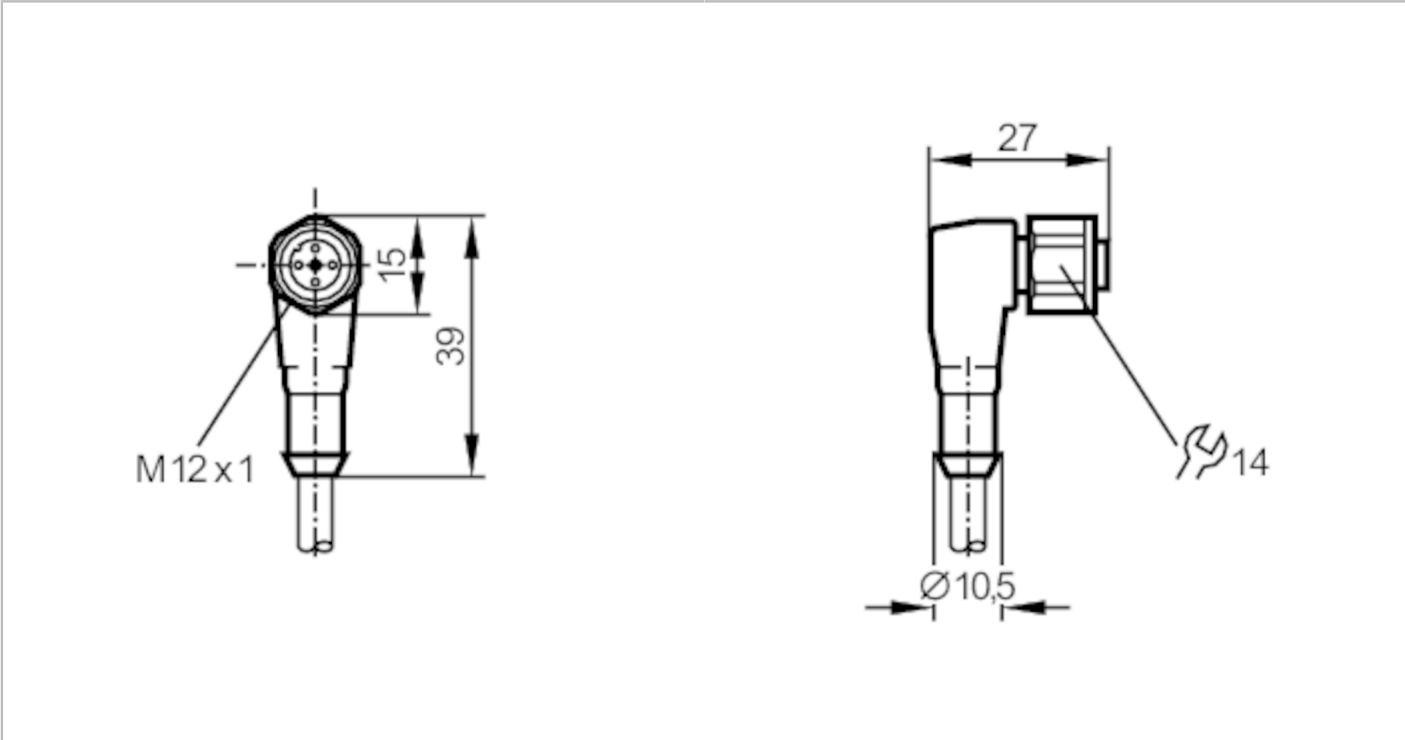

Electrical data		
Operating voltage	[M]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PVC, orange, Ø 5 mm; 2 x 0.34 mm² (42 x Ø 0.1 mm)		
Electrical connection - socket		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: stainless steel (1.4404 / 316L)

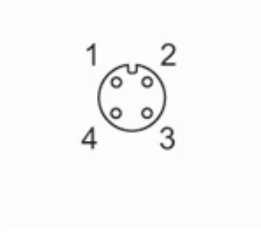


E10334



Connecting cable with socket

ADOAH040VAS0010E02

Connection

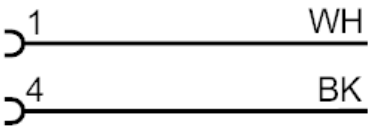

BK =	Core colours :
WH =	black
	white