

E10346




Wirable plug

SSTA040MSSFKPG

Article no longer available - archive entry

Alternative articles: E11505
When selecting an alternative article and accessories please note that technical data may differ!

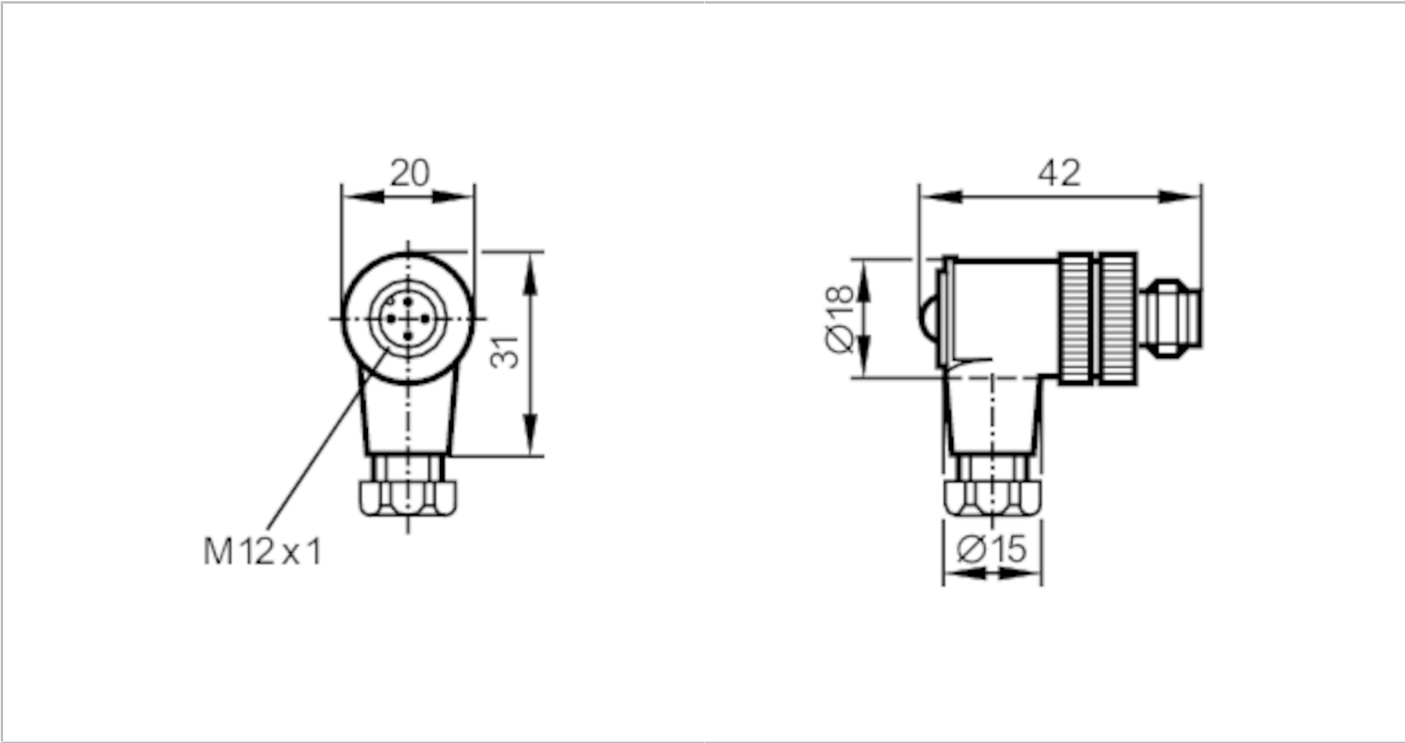

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Materials		PBT
Moulded-body material		PBT
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10346



Wirable plug

SSTA040MSSFKPG

Electrical connection

terminals: ...0.5 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PBT; Locking: brass, nickel-plated



Connection

