

E10353




Connecting cable with socket

ADOGF030MSS0002A03

Article no longer available - archive entry

Alternative articles: E11486
When selecting an alternative article and accessories please note that technical data may differ!

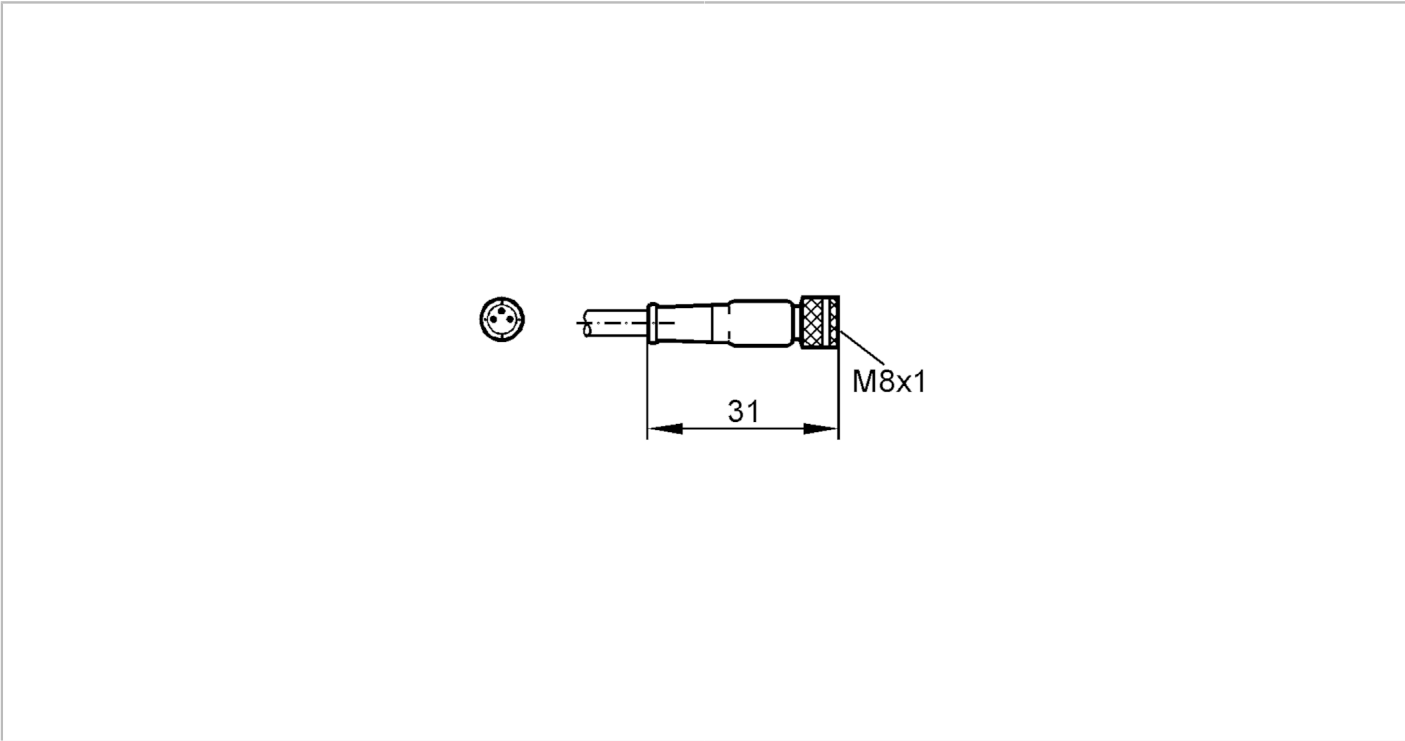

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10353



Connecting cable with socket

ADOGF030MSS0002A03

Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

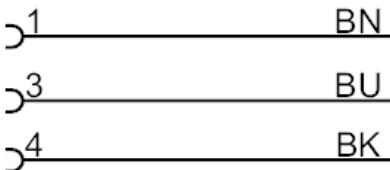

BN = Core colours : brown
BK = black
BU = blue