


Connecting cable with socket

ADOAH040MSN0002A04

Article no longer available - archive entry

Alternative articles: ENC04A

When selecting an alternative article and accessories please note that technical data may differ!

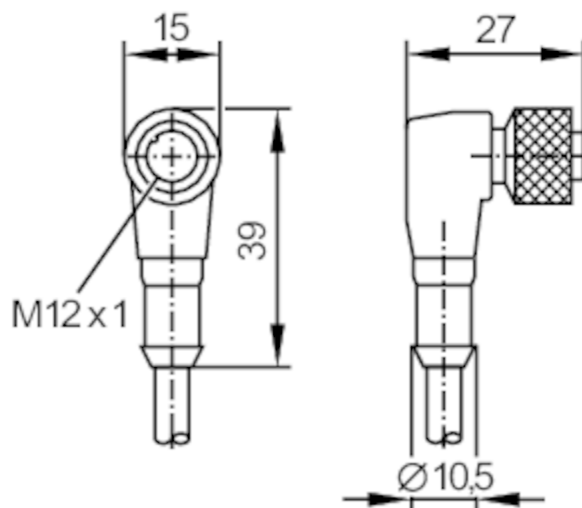

Application

Application	Ex zone 1
-------------	-----------

Electrical data

Operating voltage	[V]	< 15 DC
-------------------	-----	---------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Safety classification

Max. internal capacitance	[nF]	0.196
---------------------------	------	-------

Max. internal inductance	[µH]	4
--------------------------	------	---

Mechanical data

Dimensions	[mm]	27 x 15 x 39
------------	------	--------------

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.
	The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity	1 pcs.
---------------	--------

E10355



Connecting cable with socket

ADOAH040MSN0002A04

Electrical connection


Cable: 2 m, PUR / PVC, blue, Ø 5 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

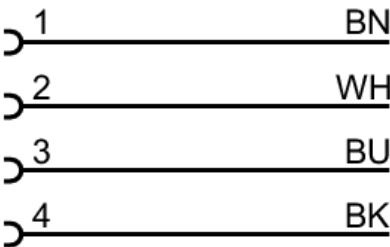

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white