




Connecting cable with socket

ADOGH040MSN0002A04

Article no longer available - archive entry

Alternative articles: ENC01A  
When selecting an alternative article and accessories please note that technical data may differ!

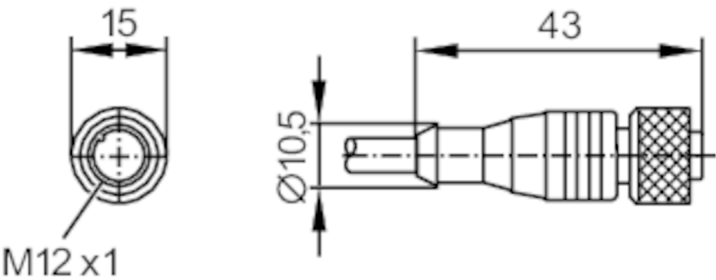

Application		
Application		Ex zone 1
Electrical data		
Operating voltage	[V]	< 15 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Safety classification		
Max. internal capacitance	[nF]	0.196
Max. internal inductance	[µH]	4
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Materials		TPU blue
Moulded-body material		TPU, blue
Material nut		brass, nickel-plated
Remarks		
Remarks		When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.
Pack quantity		1 pcs.

# E10357



## Connecting cable with socket

ADOGH040MSN0002A04

### Electrical connection


Cable: 2 m, PUR / PVC, blue, Ø 5 mm; 4 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, blue; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



### Connection

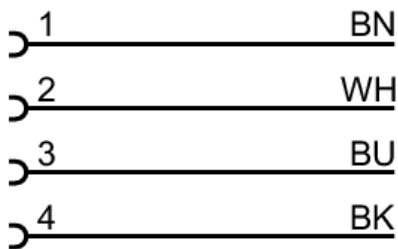

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white