


## Connecting cable with socket

ADOGH040MSN0005A04

Article no longer available - archive entry

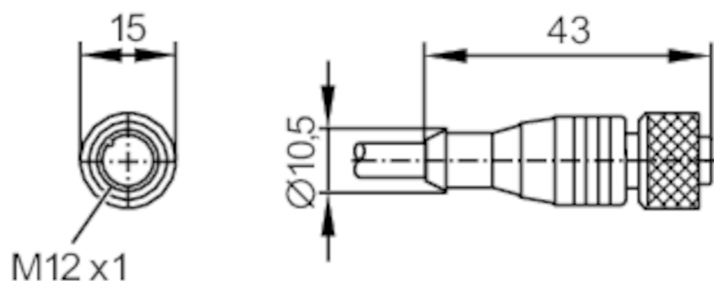

## Application

Application

Ex zone 1

## Electrical data

Operating voltage

[V]

&lt; 15 DC

## Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

## Safety classification

Max. internal capacitance

[nF]

0.49

Max. internal inductance

[µH]

10

## Mechanical data

Dimensions

[mm]

15 x 15 x 43

Materials

TPU blue

Moulded-body material

TPU, blue

Material nut

brass, nickel-plated

## Remarks

Remarks

When using sockets in hazardous areas (ATEX)  
there are special requirements regarding wiring.

The requirements of the applicable installation regulations must  
be absolutely adhered to by the user on his own responsibility.

Pack quantity

1 pcs.

# E10358



## Connecting cable with socket

ADOGH040MSN0005A04

### Electrical connection


Cable: 5 m, PUR / PVC, blue, Ø 5 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, blue; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



### Connection

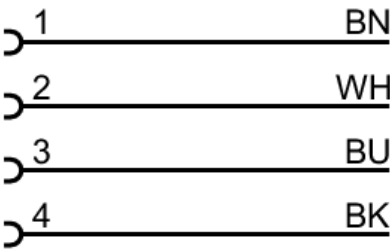

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white