




Connection cable

VDOAH042MSS0003A04STAH040MSS

Article no longer available - archive entry

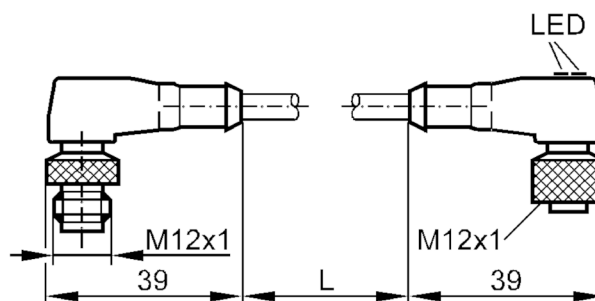

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	1 x LED, green
	operation	1 x LED, yellow

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10375




Connection cable

VDOAH042MSS0003A04STAH040MSS

Electrical connection

Cable: 3 m, PUR / PVC, orange; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

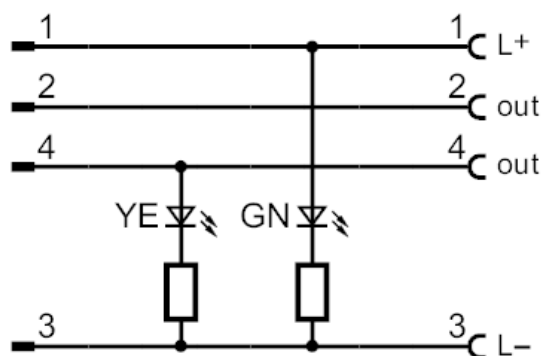

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

