


# E10376



## Connection cable

VDOAH042MSS0001A04STAH040MSS

Article no longer available - archive entry

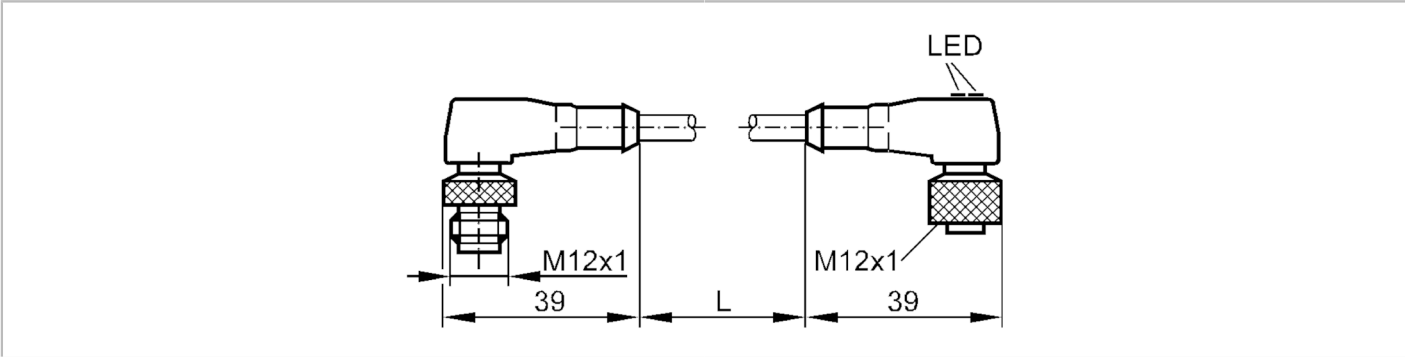

### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
|-------------------|-----|------------|

### Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |                      |
|-----------------------|----------------------|
| Materials             | TPU                  |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |

### Displays / operating elements


|         |                  |                 |
|---------|------------------|-----------------|
| Display | switching status | 1 x LED, green  |
|         | operation        | 1 x LED, yellow |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

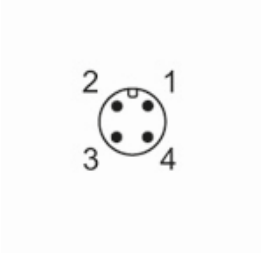

# E10376




## Connection cable

VDOAH042MSS0001A04STAH040MSS

### Electrical connection

Cable: 1 m, PUR / PVC, orange; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

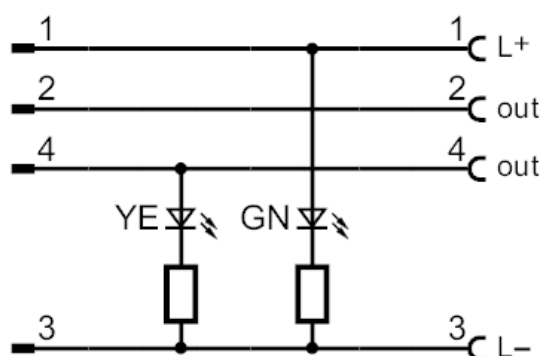

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

