


Connecting cable with socket

ADOGH040MSS0010A02

Article no longer available - archive entry

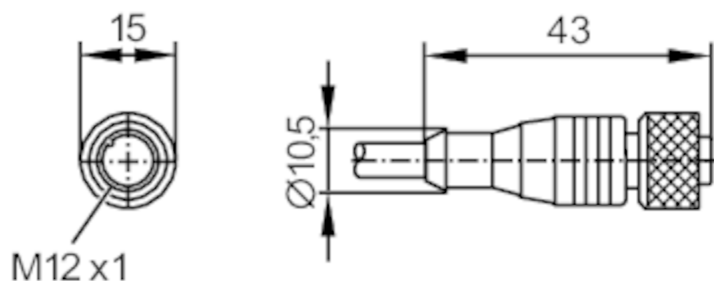

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 43
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm² (180 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

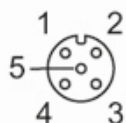


E10394



Connecting cable with socket

ADOGH040MSS0010A02

Connection

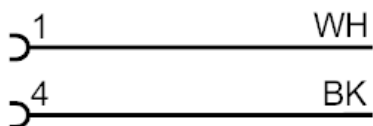

BK =	Core colours :
WH =	black
	white