

E10395




Connection cable

VDOAH042MSS00,6A04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC036
When selecting an alternative article and accessories please note that technical data may differ!

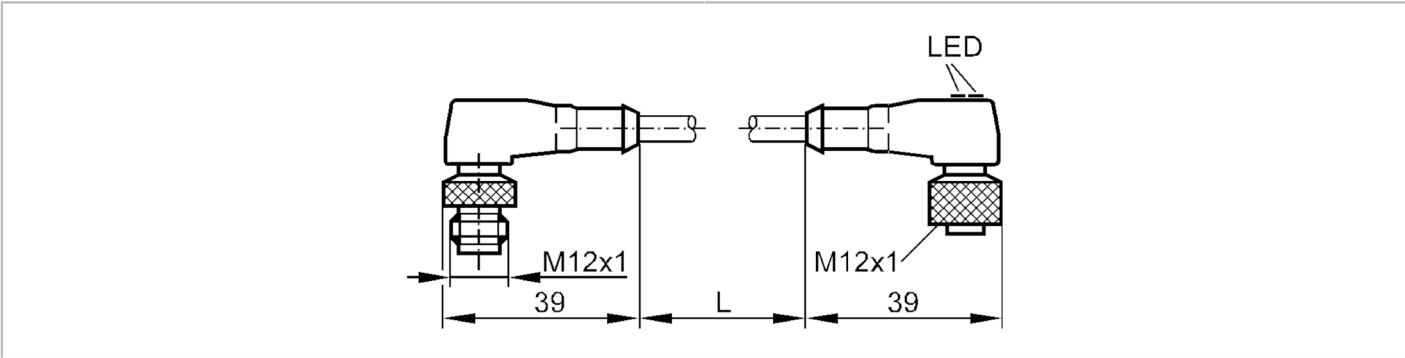

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements


Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

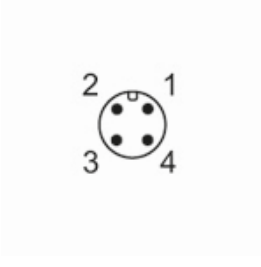

E10395



Connection cable

VDOAH042MSS00,6A04STAH040MSS

Electrical connection

Cable: 0.6 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

