


# E11427



## Jumper cable with valve plug

VVDAC031MSS00,6H03STGH030MSS

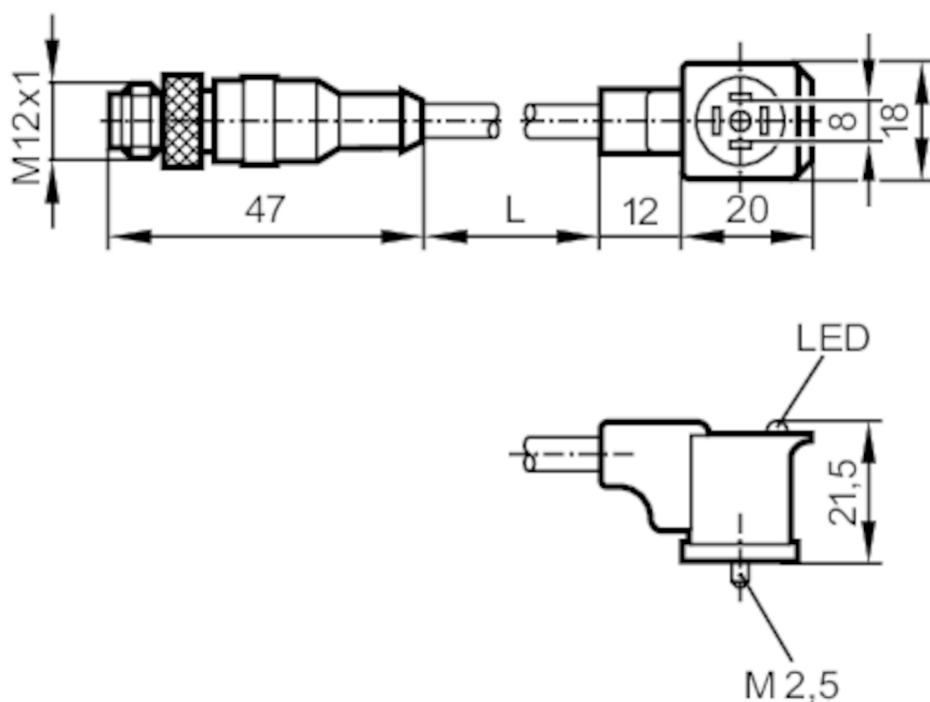

### Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes                                                    |

### Electrical data

|                         |     |            |
|-------------------------|-----|------------|
| Operating voltage       | [V] | < 24 AC/DC |
| Overvoltage protection  |     | yes; (VDR) |
| Max. current load total | [A] | 3          |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...80 |
| Protection          |      | IP 65    |

### Mechanical data

|                       |     |                      |
|-----------------------|-----|----------------------|
| Weight                | [g] | 59.2                 |
| Materials             |     | PUR                  |
| Moulded-body material |     | PUR                  |
| Material nut          |     | brass, nickel-plated |

### Displays / operating elements

|         |           |                 |
|---------|-----------|-----------------|
| Display | operation | 1 x LED, yellow |
|---------|-----------|-----------------|

### Аксессуары

|                |                     |
|----------------|---------------------|
| Items supplied | screw               |
|                | panel for labelling |

# E11427



## Jumper cable with valve plug

VVDAC031MSS00,6H03STGH030MSS

### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm<sup>2</sup> (42 x Ø 0.1 mm)

### Connection

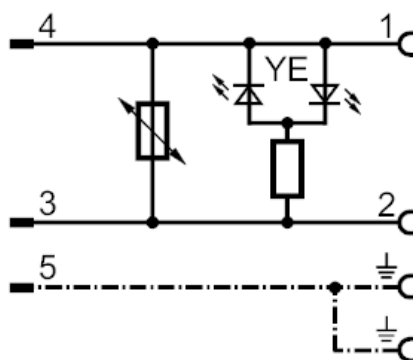

### Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

