


# E11436



## Jumper cable with valve plug

VVSAC031MSS00,3H03STGH030MSS

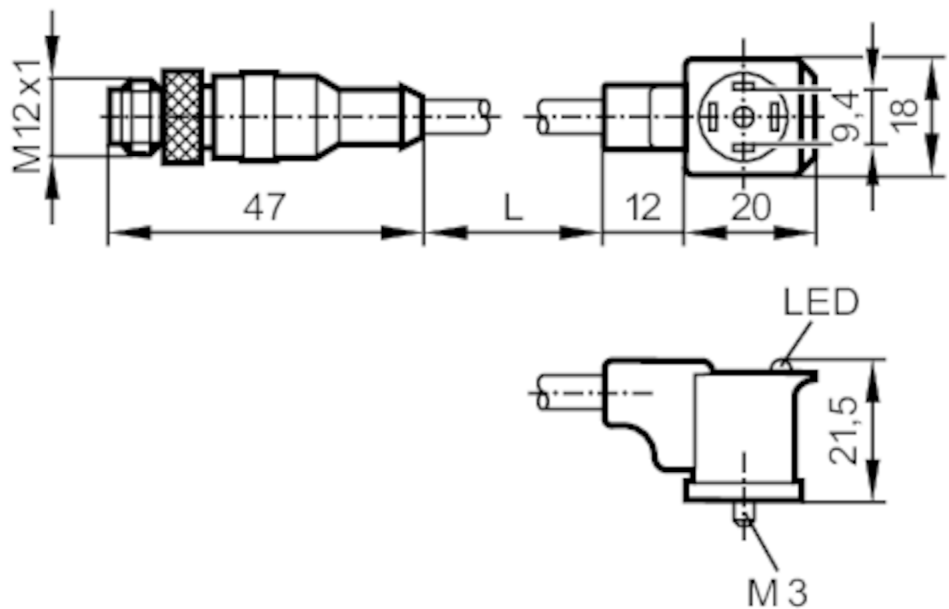

| Application                   |                                                        |                 |
|-------------------------------|--------------------------------------------------------|-----------------|
| Special feature               | Free from silicone; Halogen-free; Gold-plated contacts |                 |
| Free from silicone            | yes                                                    |                 |
| Electrical data               |                                                        |                 |
| Operating voltage             | [V]                                                    | < 24 AC/DC      |
| Overvoltage protection        | yes; (VDR)                                             |                 |
| Max. current load total       | [A]                                                    | 3               |
| Operating conditions          |                                                        |                 |
| Ambient temperature           | [°C]                                                   | -25...80        |
| Protection                    | IP 67                                                  |                 |
| Mechanical data               |                                                        |                 |
| Weight                        | [g]                                                    | 44.5            |
| Materials                     | PUR                                                    |                 |
| Moulded-body material         | PUR                                                    |                 |
| Material nut                  | brass, nickel-plated                                   |                 |
| Displays / operating elements |                                                        |                 |
| Display                       | switching status                                       | 1 x LED, yellow |
| Аксессуары                    |                                                        |                 |
| Items supplied                | screw<br>panel for labelling                           |                 |
| Remarks                       |                                                        |                 |
| Pack quantity                 | 1 pcs.                                                 |                 |



## Jumper cable with valve plug

VVSAC031MSS00,3H03STGH030MSS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

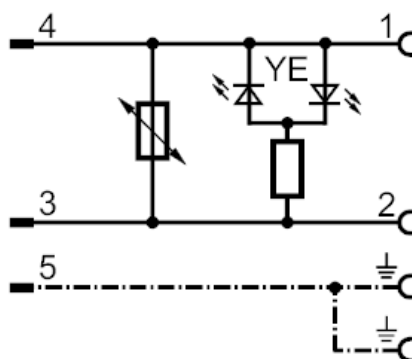

### Electrical connection - socket

Connector: 1 x valve type C industrial standard, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

