


Connection cable

VDOAF040MSS00,3H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC235

When selecting an alternative article and accessories please note that technical data may differ!

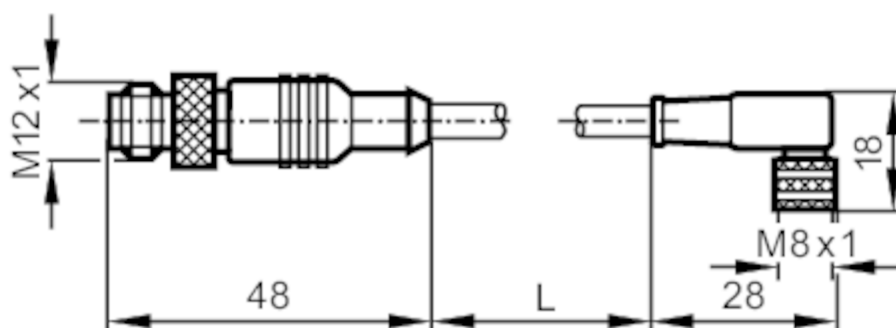

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

Mechanical data

Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11446



Connection cable

VDOAF040MSS00,3H04STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.4 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

