





Connecting cable with socket

ADOGF030MSS0002H03

Article no longer available - archive entry

Alternative articles: EVC141  
When selecting an alternative article and accessories please note that technical data may differ!

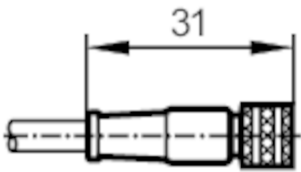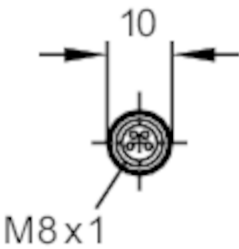

| Application             |                                                        |                      |
|-------------------------|--------------------------------------------------------|----------------------|
| Special feature         | Free from silicone; Halogen-free; Gold-plated contacts |                      |
| Free from silicone      | yes                                                    |                      |
| Electrical data         |                                                        |                      |
| Operating voltage       | [V]                                                    | < 60 AC / < 75 DC    |
| Protection class        |                                                        | III                  |
| Max. current load total | [A]                                                    | 3                    |
| Operating conditions    |                                                        |                      |
| Ambient temperature     | [°C]                                                   | -25...85             |
| Protection              |                                                        | IP 68                |
| Mechanical data         |                                                        |                      |
| Dimensions              | [mm]                                                   | 10 x 10 x 31         |
| Materials               |                                                        | PUR                  |
| Moulded-body material   |                                                        | PUR                  |
| Material nut            |                                                        | brass, nickel-plated |
| Remarks                 |                                                        |                      |
| Pack quantity           |                                                        | 1 pcs.               |



## Connecting cable with socket

ADOGF030MSS0002H03

### Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Connection



Core colours :  
 BK = black  
 BN = brown  
 BU = blue