



Connecting cable with socket

ADOGF030MSS0005H03

Article no longer available - archive entry

Alternative articles: EVC142

When selecting an alternative article and accessories please note that technical data may differ!

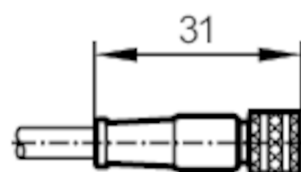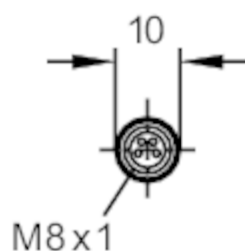

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Dimensions [mm]	10 x 10 x 31
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.



Connecting cable with socket

ADOGF030MSS0005H03

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

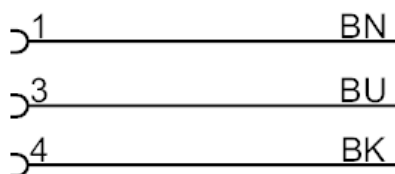

Core colours :
 BK = black
 BN = brown
 BU = blue