

Connecting cable with socket

ADOGF030VAS0010E03

Article no longer available - archive entry

Alternative articles: EVT124

When selecting an alternative article and accessories please note that technical data may differ!



Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Dimensions [mm]	10 x 10 x 31
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E11496



Connecting cable with socket

ADOGF030VAS0010E03

 
Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

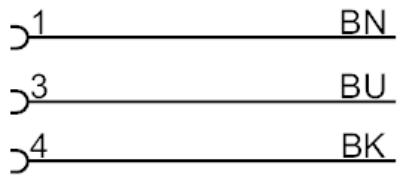

BK = Core colours :
BN = black
BU = brown
BK = blue