

Connecting cable with socket

ADOGF030VAS0025E03

Article no longer available - archive entry



Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Dimensions	[mm]	10 x 10 x 31
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11497



Connecting cable with socket

ADOGF030VAS0025E03

 
Electrical connection

Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

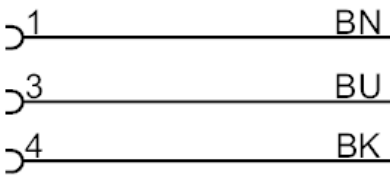

BK = Core colours :
BN = black
BU = brown
BK = blue