

Connecting cable with socket

ADOAF030VAS0005E03

Article no longer available - archive entry

Alternative articles: EVT127

When selecting an alternative article and accessories please note that technical data may differ!



Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Weight [g]	180
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E11498



Connecting cable with socket

 
ADOAF030VAS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

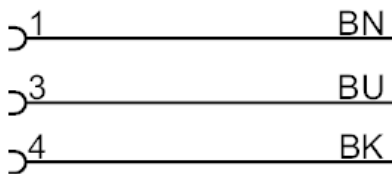

BK = Core colours :
BN = black
BU = brown
BK = blue