

Connecting cable with socket

ADOAF032VAS0005E03

Article no longer available - archive entry

Alternative articles: EVT131

When selecting an alternative article and accessories please note that technical data may differ!



Application		
Special feature	Free from silicone; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class	III	
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection	IP 68	
Mechanical data		
Dimensions	[mm]	18 x 10 x 28
Materials	PVC	
Moulded-body material	PVC	
Material nut	stainless steel (1.4404 / 316L)	
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green

E11501



Connecting cable with socket

ADOAF032VAS0005E03

Remarks

 
Pack quantity 1 pcs.

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated;
Tightening torque: 0.6...0.7 Nm



Connection

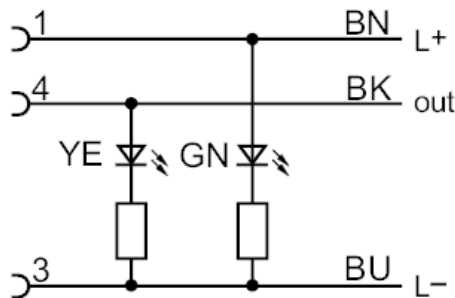

BK = Core colours :
BN = black
BU = brown
blue