


Splitter box

ZDO2H040MSS0010H05

Article no longer available - archive entry

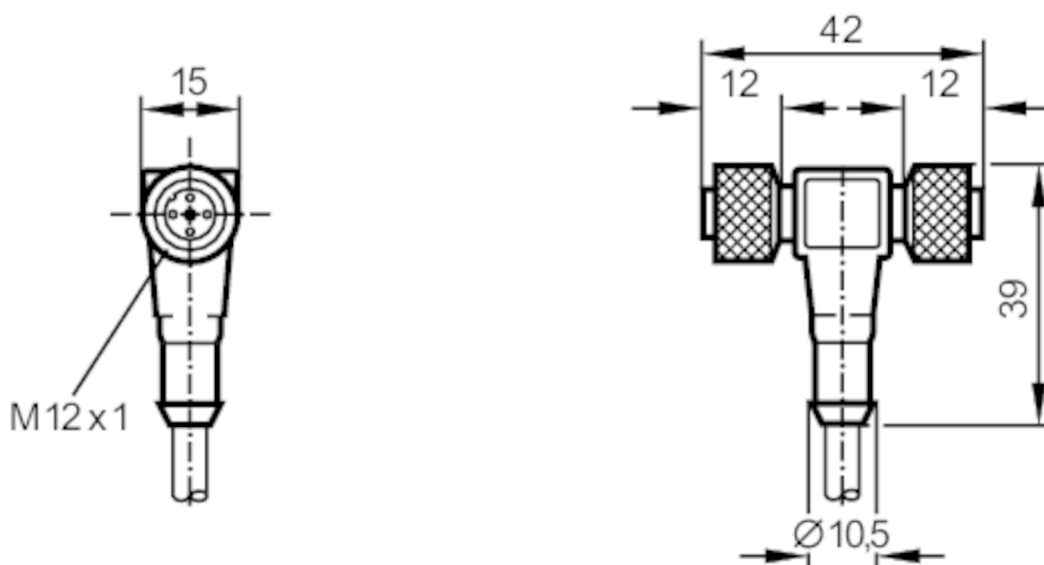

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...55 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Number of ports splitter box	2
Connector type	M12

Remarks

Pack quantity	1 pcs.
---------------	--------

E11565



Splitter box

ZDO2H040MSS0010H05

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

BN	1 (1...2)
BU	3 (1...2)
BK	4 (1)
WH	4 (2)

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white