


T-splitter

T SPLITTER M12/2XUS

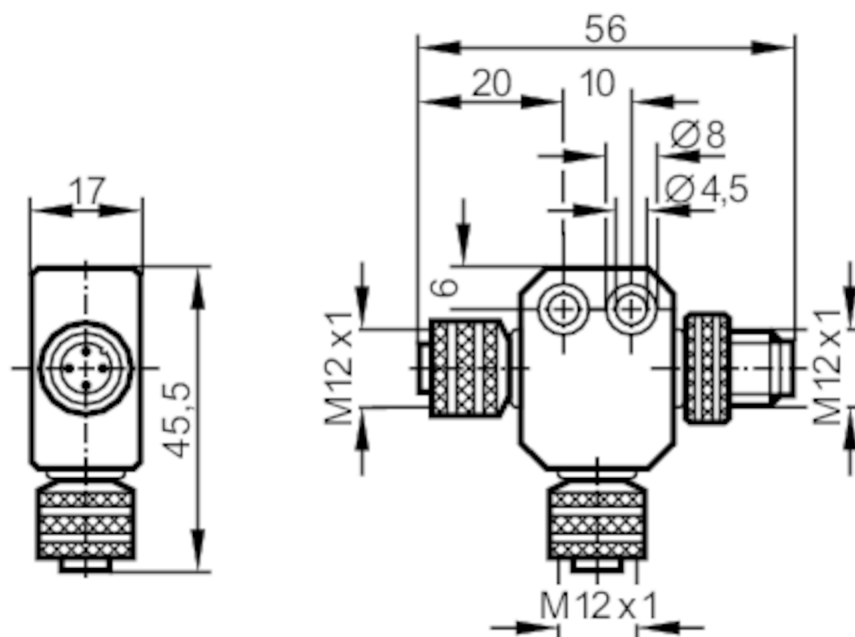

Application

Design

for pressure sensors PNI

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	3
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	38.2
Materials		PUR

Remarks

Remarks	orientation connectors A/B horizontal (for a vertical sensor)
Pack quantity	1 pcs.

T-splitter

T SPLITTER M12/2XUS

Electrical connection

Connection

