


E11570



Splitter box

ZDO6H057MSS00,5H09

Article no longer available - archive entry

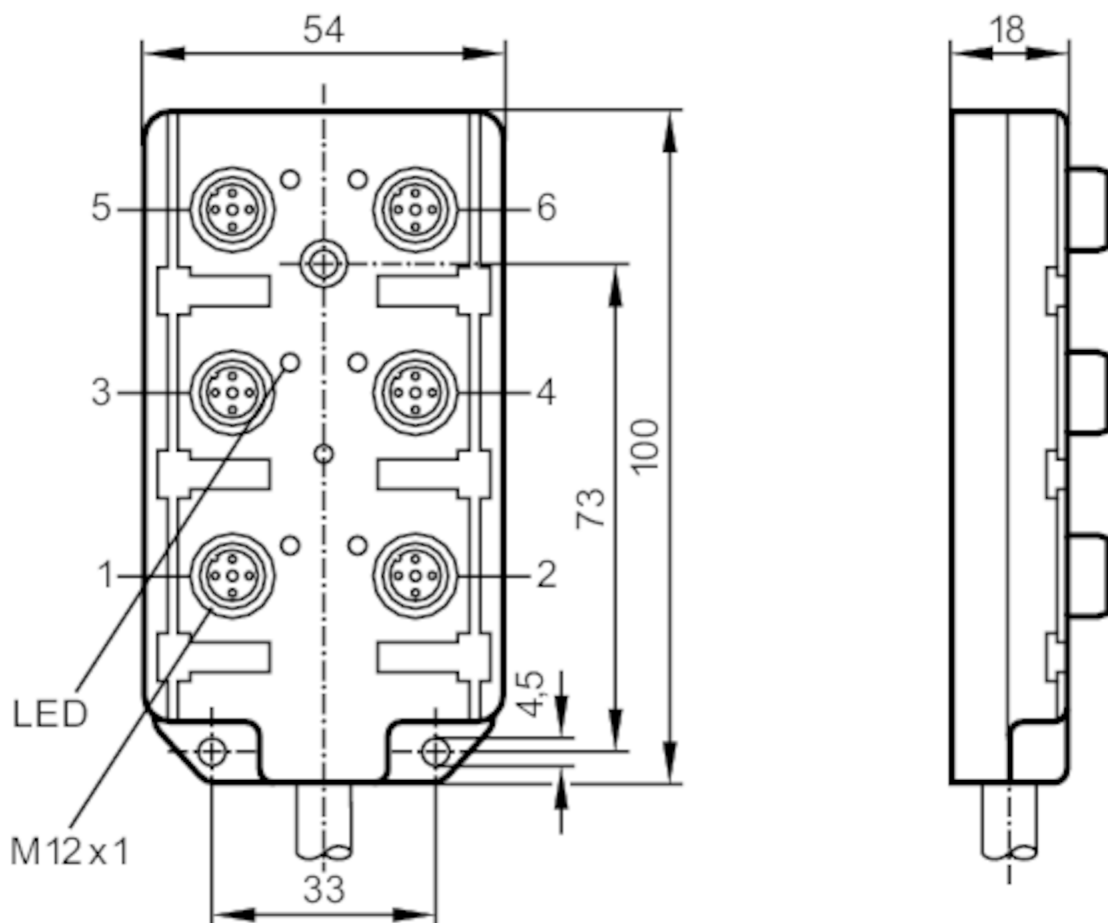

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

Mechanical data

Dimensions	[mm]	18 x 54 x 100
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		6
Connector type		M12

E11570



Splitter box

ZDO6H057MSS00,5H09

Displays / operating elements

Display	switching status	6 x LED, yellow
	operation	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection


Cable: 0.5 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

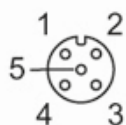

Connection

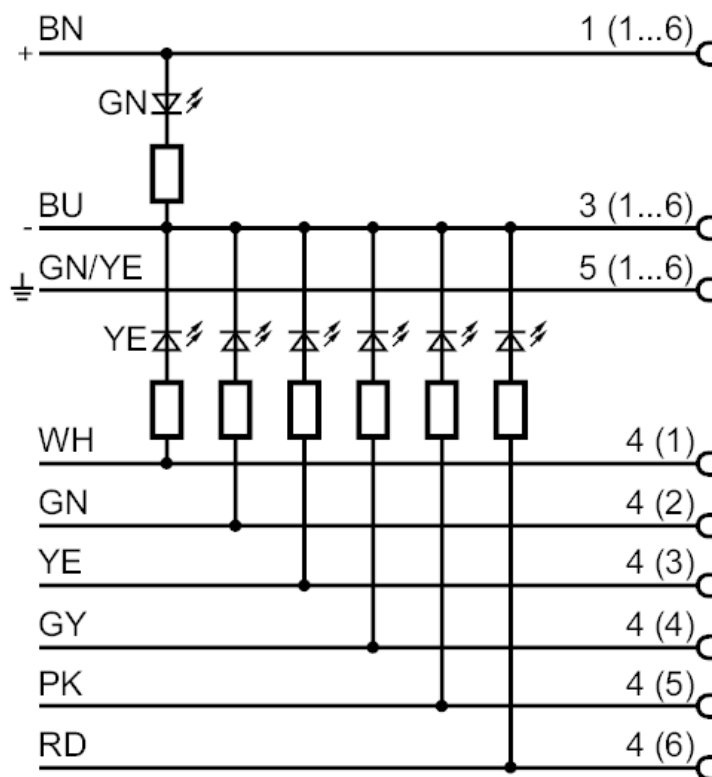

BN =	Core colours :	brown
BU =		blue
GN =		green
GN/YE =		green/yellow
GY =		grey
PK =		pink
RD =		red
WH =		white
YE =		yellow