

E11571




Splitter box

ZDO8H059MSS00,5H11

Article no longer available - archive entry

Alternative articles: EBC038
When selecting an alternative article and accessories please note that technical data may differ!

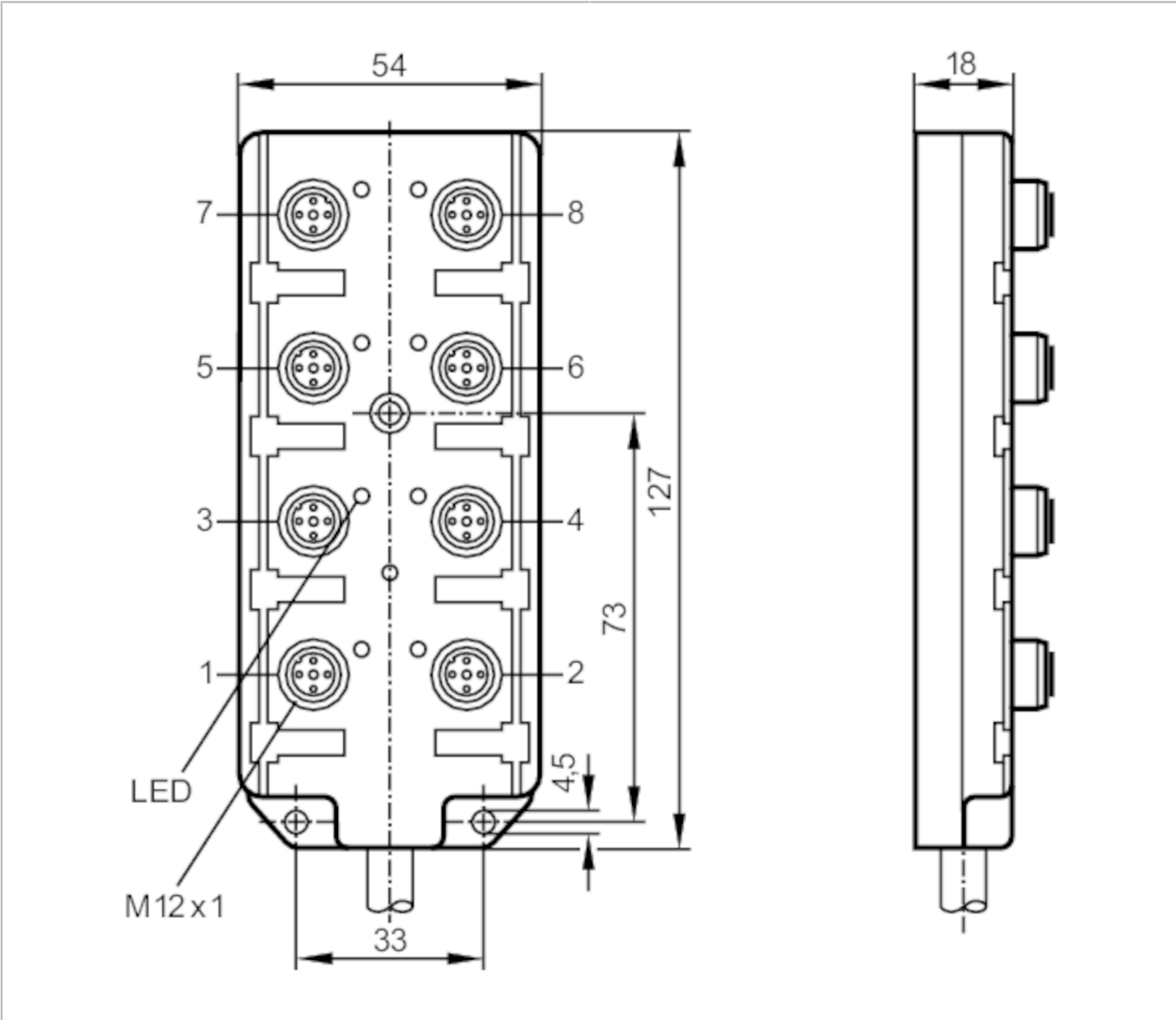

Application		
Special feature		Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

E11571



Splitter box

ZDO8H059MSS00,5H11

Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 127
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	switching status	8 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 0.5 m, PUR / PVC, Halogen-free, black, Ø 8.4 mm; 8 x 0.34 mm ² + 3 x 0.75 mm ²		
Electrical connection - slot		
Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm		

E11571



Splitter box

ZDO8H059MSS00,5H11

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow