





Socket with CAN bus terminating resistor

SDOGH050ZDAFKPG

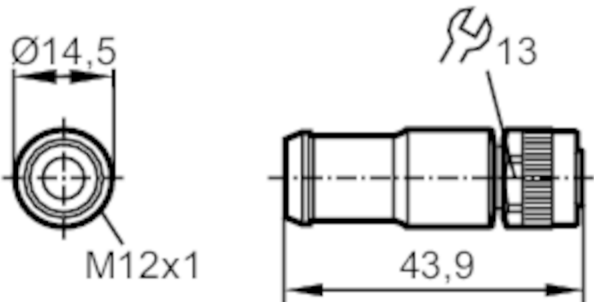

Application	
Application	CAN bus
Operating conditions	
Ambient temperature	[°C] -40...85
Protection	IP 68
Mechanical data	
Weight	[g] 7.7
Dimensions	[mm] 14.5 x 14.5 x 43.9
Materials	TPU; Sealing: FKM
Moulded-body material	TPU
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - socket	

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Tightening torque: ...0.6 Nm

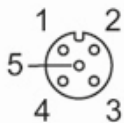

E11589



Socket with CAN bus terminating resistor

SDOGH050ZDAFKPG

Connection

