


E11627



T-splitter

T SPLITTER M12/2XUS

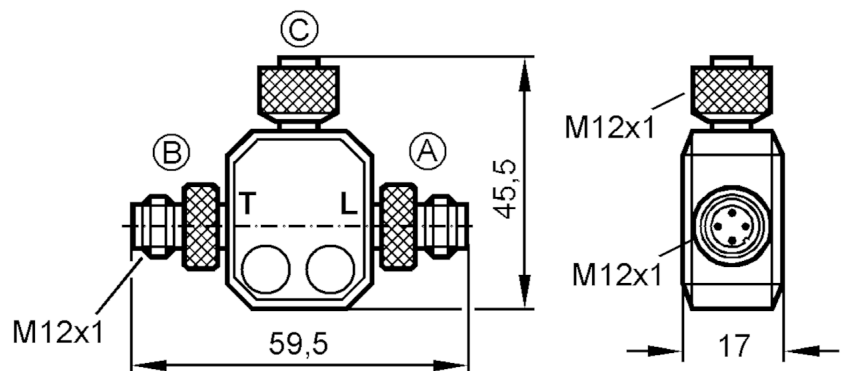


Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	3
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	39.7
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Аксессуары		
Items supplied		захисні заглушки: 1
Remarks		
Pack quantity		1 pcs.

T-splitter

T SPLITTER M12/2XUS

Electrical connection

Connection

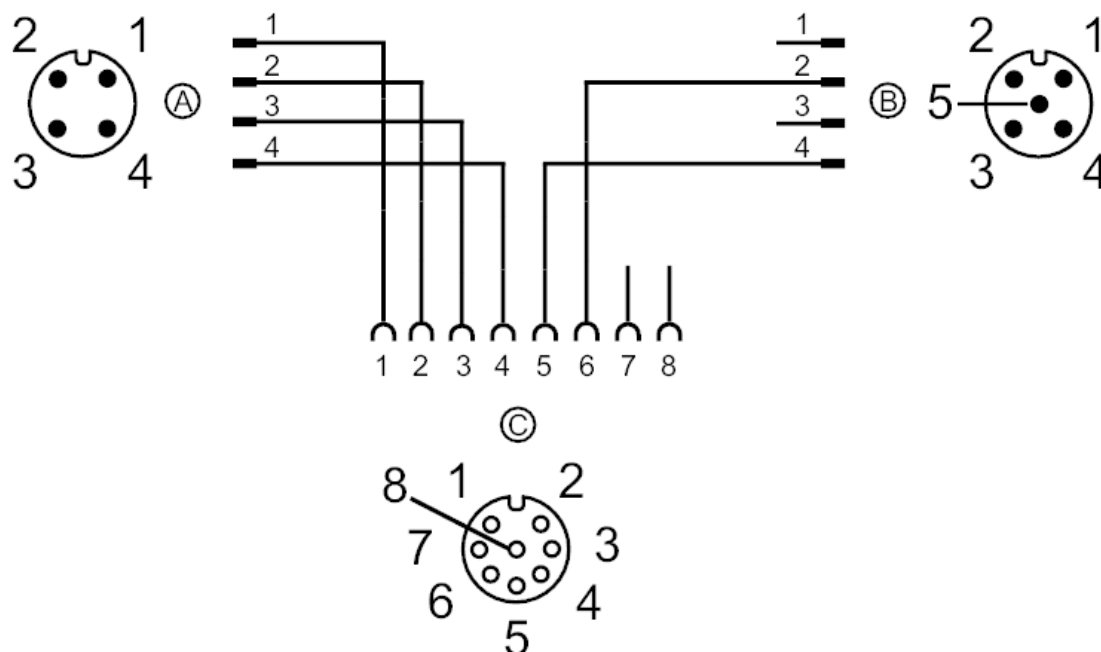

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated