


E11652



Jumper cable with valve plug

AVDAB031PLS0005H03

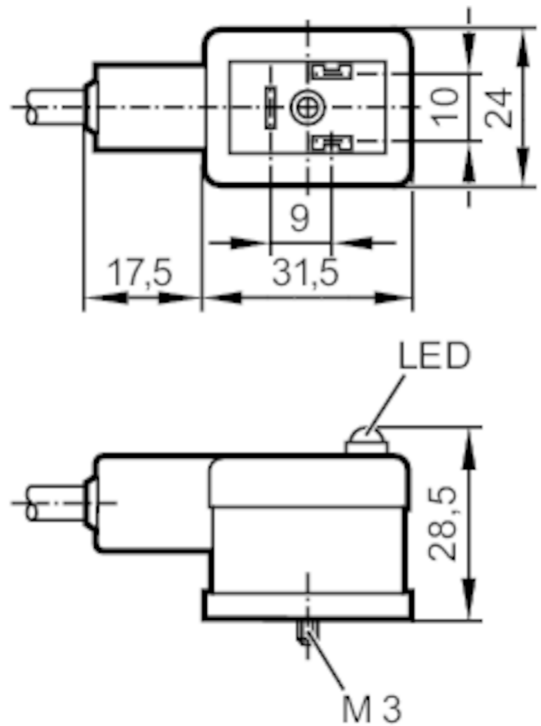

Application		
Special feature	Free from silicone; Halogen-free	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)	
Operating conditions		
Ambient temperature	[°C]	-20...80
Protection	IP 67	
Mechanical data		
Weight	[g]	255.8
Dimensions	[mm]	28.5 x 24 x 49
Materials	PP; FKM	
Moulded-body material	PP / FPM	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	1 x LED, yellow
Remarks		
Pack quantity	1 pcs.	

E11652



Jumper cable with valve plug

AVDAB031PLS0005H03

Electrical connection


Cable: 5 m, PUR, Halogen-free, Ø 6.6 mm; 3 x 0.5 mm² / AWG 20

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PP / FPM; Locking: brass, nickel-plated



Connection

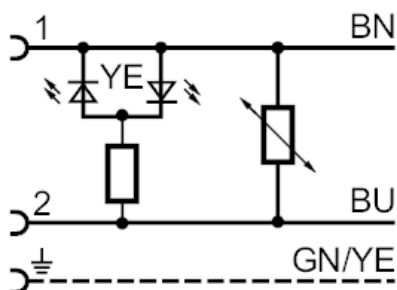

BN =	Core colours :
BU =	brown
GN/YE =	blue
	green/yellow