


E11655



Jumper cable with valve plug

AVSAC031PLS0005H03

Article no longer available - archive entry

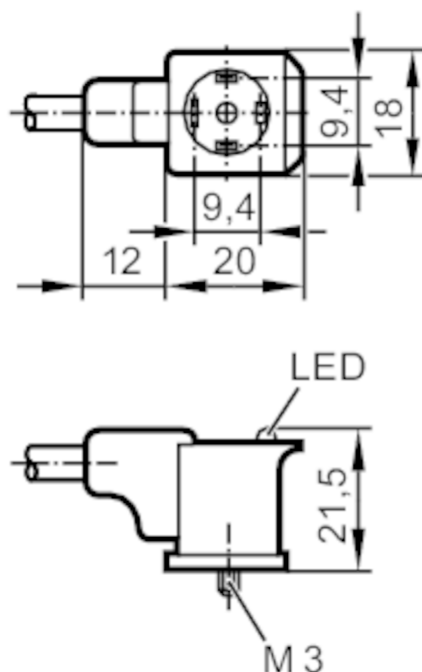

Application

Special feature	Free from silicone; Halogen-free
Free from silicone	yes

Electrical data

Operating voltage [V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)

Operating conditions

Ambient temperature [°C]	-20...80
Protection	IP 67

Mechanical data

Dimensions [mm]	21.5 x 18 x 32
Materials	PP; FKM
Moulded-body material	PP / FPM
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11655



Jumper cable with valve plug

AVSAC031PLS0005H03

Electrical connection


Cable: 5 m, PUR, Halogen-free, Ø 6.6 mm; 3 x 0.5 mm² / AWG 20

Electrical connection - socket

Connector: 1 x valve type C industrial standard, angled; Moulded body: PP / FPM; Locking: brass, nickel-plated



Connection

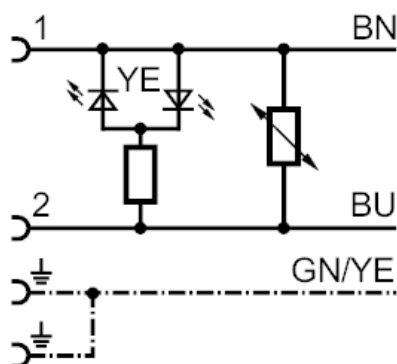

BN =
BU =
GN/YE =

Core colours :
brown
blue
green/yellow