


E11656



Connecting cable with socket

ADOAA030MSS0005H03

Article no longer available - archive entry

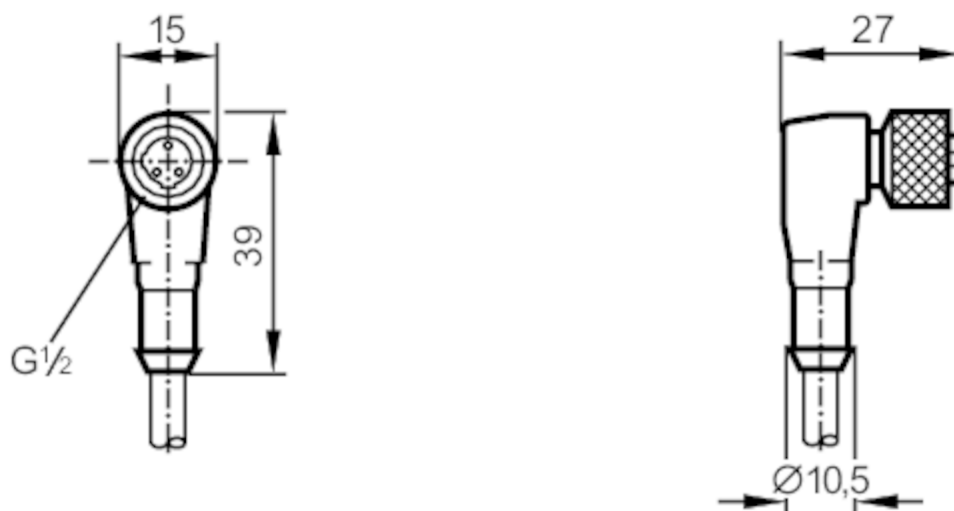

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 250 AC / < 300 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E11656



Connecting cable with socket

ADOAA030MSS0005H03

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.6 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: TPU; Locking: brass, nickel-plated



Connection

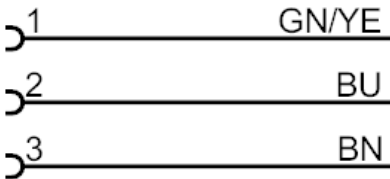

BN =	Core colours :
BU =	brown
GN =	blue
YE =	green
	yellow