


Y connection cable

YDOAH040MSS0,25H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC503

When selecting an alternative article and accessories please note that technical data may differ!

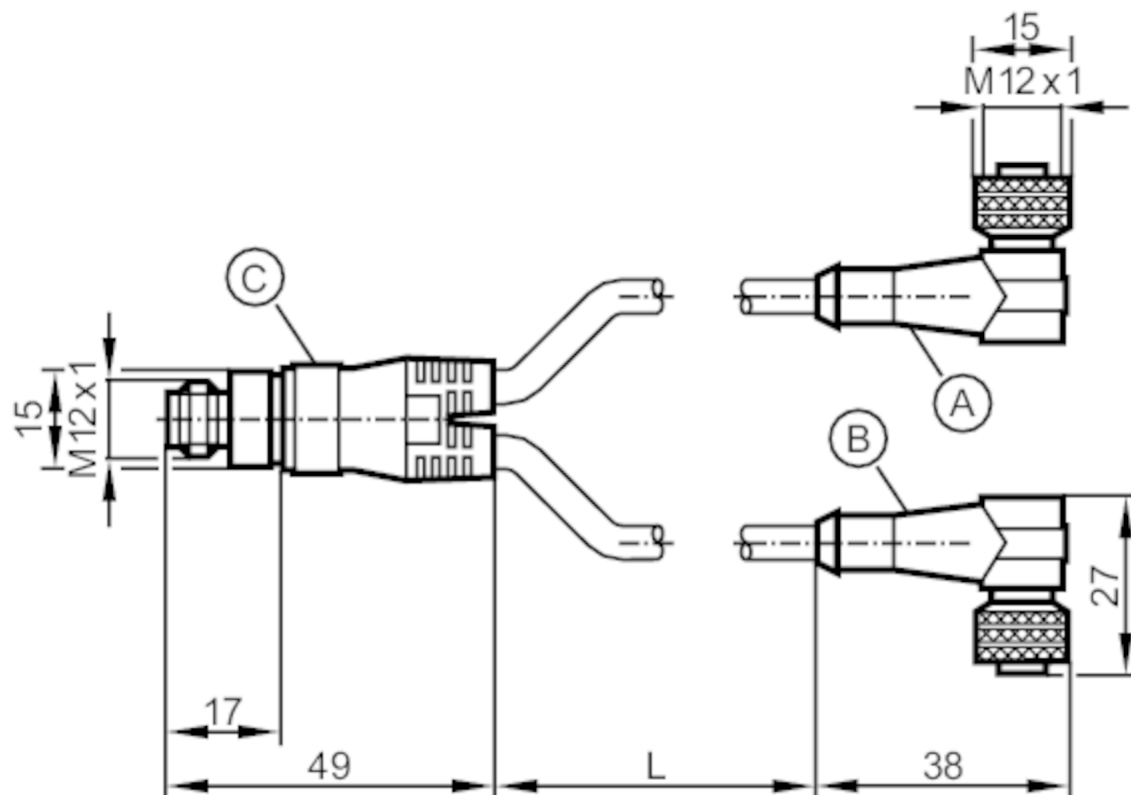

3-1 input cable grey
3-2 octavis cable black

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Max. current load total

[A]

4

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 68

Mechanical data

Weight

[g]

65

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Number of ports splitter box

2

Remarks

Pack quantity

1 pcs.



Y connection cable

YDOAH040MSS0,25H04STGH040MSS

Electrical connection


Cable: 0.25 m, PUR, Halogen-free, black, Ø 5 mm; 5 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

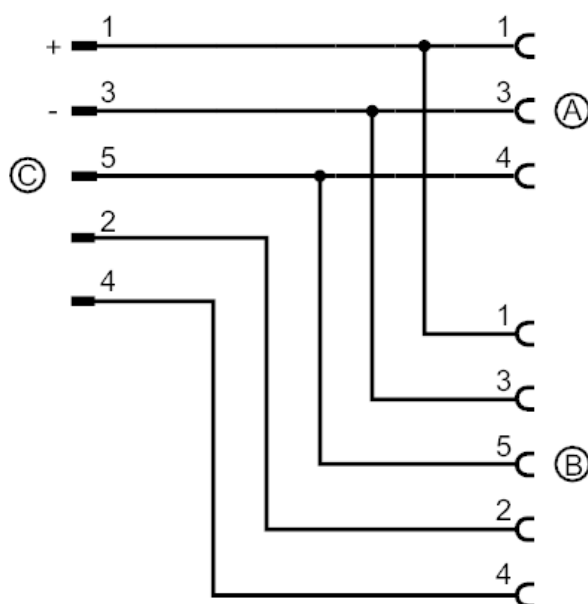

Electrical connection - socket

Connector: 2 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

