


E11685



Bulk cable

CABLE/ 50M/ PUR/4X0,34/BK

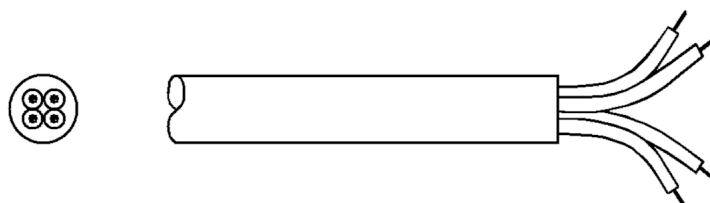

Application

Special feature

Halogen-free; Drag chain suitability

Operating conditions

Ambient temperature

[°C]

-40...90

Mechanical data

Weight

[g]

1612

Drag chain suitability

yes

Drag chain suitability

bending radius for flexible use

min. 10 x cable diameter

travel speed

max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²

bending cycles

> 5 Mio.

torsional strain

± 180 °/m

Remarks

Pack quantity

1 pcs.

Electrical connection

Cable: 50 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm², PP